




- Hand brushes are used for manual cleaning, scouring, dust removal, stripping, descaling, honing or deburring operations on cylindrical surfaces: inside tubes, bottles, pin holes, rivet holes, tapped holes, secant holes, etc.
- These brushes can be used in a wide range of industries: mechanical (machine tools, maintenance), food processing, pharmaceutical and medical.

In practice

- Scrub the walls of the element to be cleaned using a rotating and back-and-forth motion.

Advice

- To prevent the bristles of the brush from twisting, we recommend that you choose one that the diameter is 10 to 15% larger than the diameter of the hole you wish to clean.

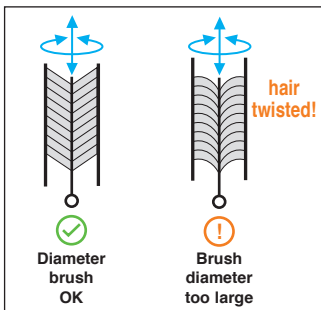

It's the end of the brush that works, not the edge.
It needs room to stand up straight

Deburring and stripping stainless steel

GPLSS



- **Stainless steel deburring brushes**

- Materials:

- Twisted galvanised steel
- Stainless steel covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

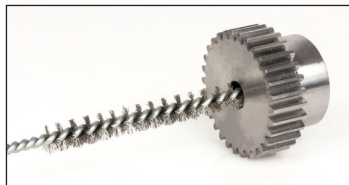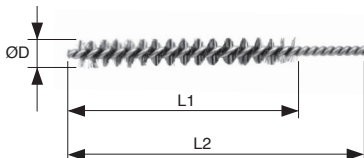

Deburring a gear bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List		-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Overall length L2	Stock*	Price each 1 to 9
GPL5-100/SS	5	100	300	✓	12,23 €
GPL8-100/SS	8	100	300	✓	10,46 €
GPL10-100/SS	10	100	300	✓	9,55 €
GPL12-100/SS	12	100	300	✓	9,55 €
GPL15-100/SS	15	100	300	✓	9,67 €
GPL20-100/SS	20	100	300	✓	10,70 €
GPL25-100/SS	25	100	300	✓	10,11 €

*Depending on availability - Dimensions in mm

- Deburring and cleaning brush for all materials

- Materials:

Twisted galvanised steel



Galvanized steel twist

Steel covering



Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

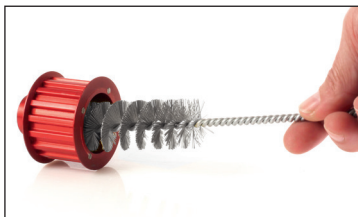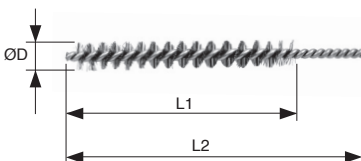

Stripping of a pulley bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/AC	5	100	300	✓	12,42 €
GPL8-100/AC	8	100	300	-	8,07 €
GPL10-100/AC	10	100	300	✓	8,07 €
GPL12-100/AC	12	100	300	-	8,22 €
GPL15-100/AC	15	100	300	-	8,53 €
GPL20-100/AC	20	100	300	-	10,08 €
GPL25-100/AC	25	100	300	-	10,08 €

*Depending on availability - Dimensions in mm

For deburring and stripping softer materials

GPL_{BR}

- **Deburring and stripping brushes for aluminium, bronze and brass**




- Materials:

Twisted galvanised steel

Brass covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

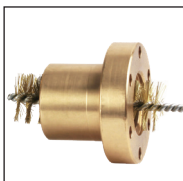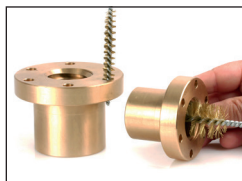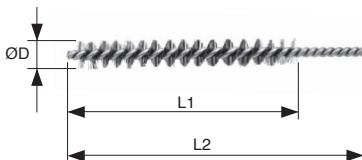

Deburring a trapezoidal nut

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/BR	5	100	300	✓	12,23 €
GPL8-100/BR	8	100	300	-	10,24 €
GPL10-100/BR	10	100	300	-	9,22 €
GPL12-100/BR	12	100	300	✓	9,28 €
GPL15-100/BR	15	100	300	✓	9,28 €
GPL20-100/BR	20	100	300	✓	9,84 €
GPL25-100/BR	25	100	300	✓	9,84 €

*Depending on availability - Dimensions in mm




- Deburring brushes for soft materials

- Materials:

- Twisted galvanised steel
- Nylon covered

Applications

- Gentle cleaning of hollow containers (tubes, bottles, holes)
- Gentle cleaning of hard-to-reach areas

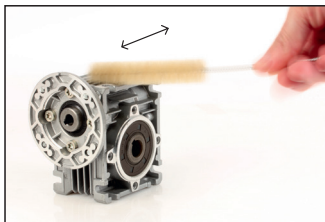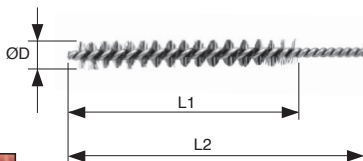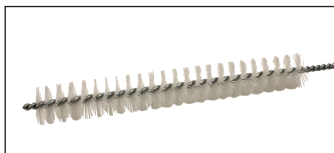

Cleaning the cooling fins of a gearbox

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL4-100/NY	4	100	300	✓	7,76 €
GPL6-100/NY	6	100	300	✓	5,11 €
GPL8-100/NY	8	100	300	✓	5,14 €
GPL10-100/NY	10	100	300	✓	5,18 €
GPL12-100/NY	12	100	300	✓	5,21 €
GPL15-100/NY	15	100	300	✓	5,27 €
GPL20-100/NY	20	100	300	✓	5,32 €
GPL25-100/NY	25	100	300	✓	5,41 €
GPL30-100/NY	30	100	300	✓	5,59 €
GPL40-100/NY	40	100	300	✓	5,79 €

*Depending on availability - Dimensions in mm

- Brushes for the cleaning and removal of dust

- Materials:




Twisted galvanised steel
Hog bristle silk covering

Application

- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas

Advantage

- Anti-static

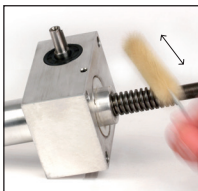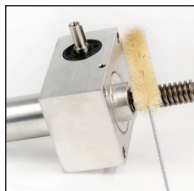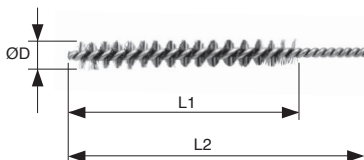

Cleaning of hard-to-reach areas

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL15-100/SO	15	80	300	✓	8,53 €
GPL20-100/SO	20	80	300	-	10,08 €
GPL25-100/SO	25	80	300	✓	8,99 €

*Depending on availability - Dimensions in mm

Our other products



SFWR
End support, Surface mounting



GE_C
Spherical bushing,
Hard chromium / PTFE



VRM
Female swivelling
lifting rings, Female
swivelling



DOMI50
Domino 50 adjustable
slide, Slide DOMILINE
50



UGAC_UGET
Actuator guide kit,
Coupling for threaded
cylinder end




Gal-cardan
Single universal joint
eco series, Low duty



BEAS
Knob star grip
antistatic, Star, anti-
static




PCS50K
Chain sprocket with
hardened teeth,
12.7mm (DIN08B-1)

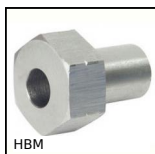

HBM
Adjustment bushing
for half-rail guide,
Adjustment bushing



PTRSS
Idler chain sprocket,
For hostile
environments

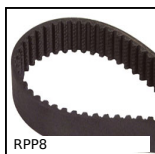


RPP8
RPP heavy duty
timing belt, RPP8



PPF
Indexing plunger with
flange, with drilled
flange

 
Complementary products




GPLss
Brush, stainless steel



 GPLbr
Brush, brass



GPLny
Brush, nylon

 

GPLso
Brush, silk