

Hand brushes

GPL

Technical data




- Hand brushes are used for manual cleaning, scouring, dust removal, stripping, descaling, honing or deburring operations on cylindrical surfaces: inside tubes, bottles, pin holes, rivet holes, tapped holes, secant holes, etc.
- These brushes can be used in a wide range of industries: mechanical (machine tools, maintenance), food processing, pharmaceutical and medical.

In practice

- Scrub the walls of the element to be cleaned using a rotating and back-and-forth motion.

Advice

- To prevent the bristles of the brush from twisting, we recommend that you choose one that the diameter is 10 to 15% larger than the diameter of the hole you wish to clean.

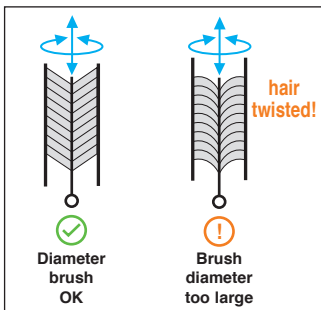

It's the end of the brush that works, not the edge.
It needs room to stand up straight

Deburring and stripping stainless steel

GPLSS



- **Stainless steel deburring brushes**

- Materials:

- Twisted galvanised steel
- Stainless steel covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

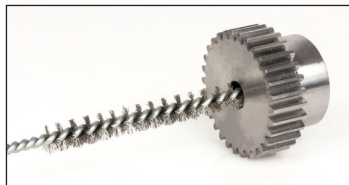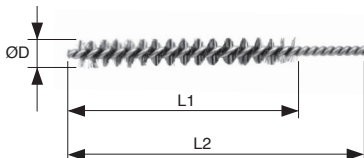

Deburring a gear bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List		-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Overall length L2	Stock*	Price each 1 to 9
GPL5-100/SS	5	100	300	✓	12,23 €
GPL8-100/SS	8	100	300	✓	10,46 €
GPL10-100/SS	10	100	300	✓	9,55 €
GPL12-100/SS	12	100	300	✓	9,55 €
GPL15-100/SS	15	100	300	✓	9,67 €
GPL20-100/SS	20	100	300	✓	10,70 €
GPL25-100/SS	25	100	300	✓	10,11 €

*Depending on availability - Dimensions in mm

- Deburring and cleaning brush for all materials



- Materials:

- Twisted galvanised steel
- Galvanized steel twist
- Steel covering



Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

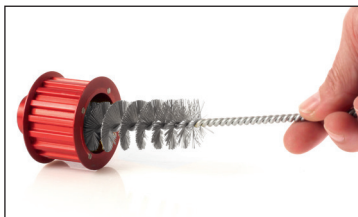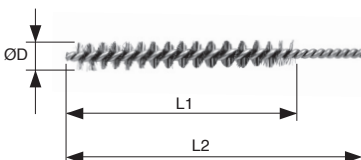

Stripping of a pulley bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/AC	5	100	300	✓	12,42 €
GPL8-100/AC	8	100	300	-	8,07 €
GPL10-100/AC	10	100	300	✓	8,07 €
GPL12-100/AC	12	100	300	-	8,22 €
GPL15-100/AC	15	100	300	-	8,53 €
GPL20-100/AC	20	100	300	-	10,08 €
GPL25-100/AC	25	100	300	-	10,08 €

*Depending on availability - Dimensions in mm

For deburring and stripping softer materials

GPL_{BR}




- Deburring and stripping brushes for aluminium, bronze and brass

- Materials:

- Twisted galvanised steel
- Brass covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

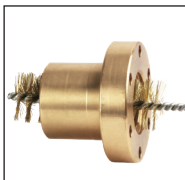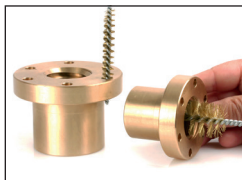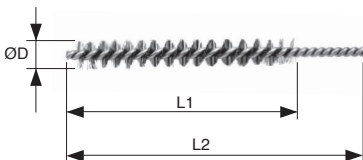

Deburring a trapezoidal nut

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/BR	5	100	300	✓	12,23 €
GPL8-100/BR	8	100	300	-	10,24 €
GPL10-100/BR	10	100	300	-	9,22 €
GPL12-100/BR	12	100	300	✓	9,28 €
GPL15-100/BR	15	100	300	✓	9,28 €
GPL20-100/BR	20	100	300	✓	9,84 €
GPL25-100/BR	25	100	300	✓	9,84 €

*Depending on availability - Dimensions in mm




- Deburring brushes for soft materials

- Materials:

- Twisted galvanised steel
- Nylon covered

Applications

- Gentle cleaning of hollow containers (tubes, bottles, holes)
- Gentle cleaning of hard-to-reach areas

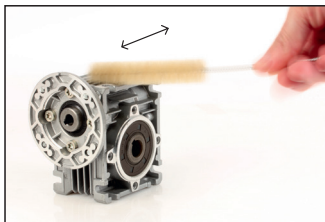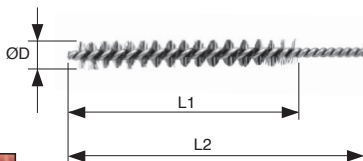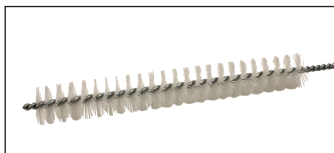

Cleaning the cooling fins of a gearbox

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL4-100/NY	4	100	300	✓	7,76 €
GPL6-100/NY	6	100	300	✓	5,11 €
GPL8-100/NY	8	100	300	✓	5,14 €
GPL10-100/NY	10	100	300	✓	5,18 €
GPL12-100/NY	12	100	300	✓	5,21 €
GPL15-100/NY	15	100	300	✓	5,27 €
GPL20-100/NY	20	100	300	✓	5,32 €
GPL25-100/NY	25	100	300	✓	5,41 €
GPL30-100/NY	30	100	300	✓	5,59 €
GPL40-100/NY	40	100	300	✓	5,79 €

*Depending on availability - Dimensions in mm

- Brushes for the cleaning and removal of dust

- Materials:




Twisted galvanised steel
Hog bristle silk covering

Application

- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas

Advantage

- Anti-static

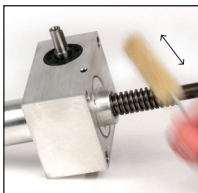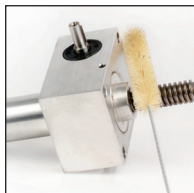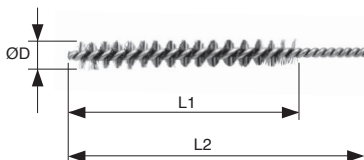

Cleaning of hard-to-reach areas

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL15-100/SO	15	80	300	✓	8,53 €
GPL20-100/SO	20	80	300	-	10,08 €
GPL25-100/SO	25	80	300	✓	8,99 €

*Depending on availability - Dimensions in mm

Our other products



AC

Strike for toggle latch,
13mm



HTD5M_25

HTD Heavy duty
timing pulley, HTD5
Steel



WING

Manually tightened
wing nut, Steel (ANSI
B18-17)



CABPVC

PVC covered
galvanised steel
cable, Galvanised
steel with



PGMT

Pull handle, Steel



BABFCFO

Ball pin socket,
Mounting collar with a
round flange



PRF_GAL

Roller for aluminium
profile, Fixing kit for
roller concentric



PTRSS

Idler chain sprocket,
For hostile
environments



CQA30

Accessory for
adjustment slide-
system, 30



MDB_MTB

Moulded plastic bevel
gear (nylon), 2:1



PWC

 
Powercoil thread
inserts, Kit Powercoil -
with or without



OPFL_OPPM


Numerical counter
accessories, Locking
clamp

Complementary products




GPLss

 Brush, stainless steel




GPLac

 Brush, steel



GPLny

Brush, nylon

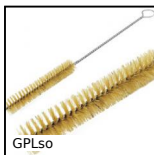

GPLso

Brush, silk