

For deburring and stripping
softer materials

GPL^{BR}

- **Deburring and stripping brushes for aluminium, bronze and brass**


- Materials:

Twisted galvanised steel

Brass covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

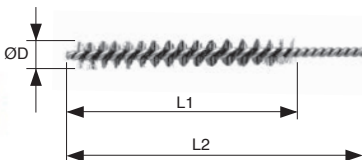

Deburring a trapezoidal nut

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/BR	5	100	300	✓	10,03 €
GPL8-100/BR	8	100	300	-	8,40 €
GPL10-100/BR	10	100	300	-	7,56 €
GPL12-100/BR	12	100	300	✓	7,61 €
GPL15-100/BR	15	100	300	✓	7,61 €
GPL20-100/BR	20	100	300	✓	8,07 €
GPL25-100/BR	25	100	300	✓	8,07 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



G2

Steel spur gear, Steel
20NCD2



HBM

Adjustment bushing
for half-rail guide,
Adjustment bushing



MDB_MTB

Moulded plastic bevel
gear (nylon), 2:1



 
APB_T

Adjusting rod for
clamp - Female, Bored



GE

Toggle latches,
Standard



PRFbou

Emergency release
button for aluminium
profile, Emergency
release bu...



BH01

Single housed
bearing, Bearing fitted
with adhesive



PT881

Drive sprocket for slat
top chain, Range 881



GB-RA

Brass spur gear, Brass
CuZn39Pb3




SF_ZZ

Deep groove ball
bearing, Stainless
steel



FF40


Offset spur gear
reducer, from 59 to
210 Nm

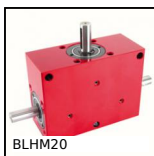

BLHM20


Right angled gearbox,
double output shafts,
up to 1.77 Nm

 Complementary products




GPLss

 Brush, stainless steel




GPLac

Brush, steel

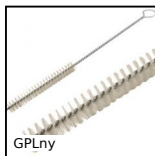

GPLny

Brush, nylon

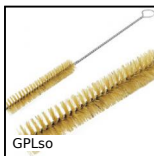

GPLso

Brush, silk