

Nylon brush

GPLNY

For mechanical and soft cleaning

- **Deburring brushes for soft materials**

- **Materials:**




Twisted galvanised steel

Nylon covered

Applications

- Gentle cleaning of hollow containers
(tubes, bottles, holes)

- Gentle cleaning of hard-to-reach areas

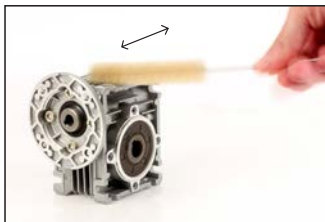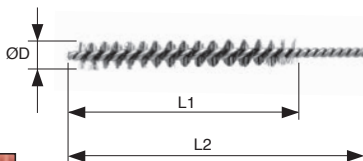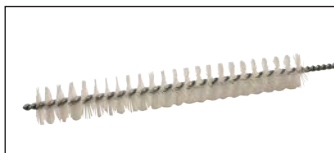

Cleaning the cooling fins of a gearbox

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL4-100/NY	4	100	300	✓	6,37 €
GPL6-100/NY	6	100	300	✓	4,19 €
GPL8-100/NY	8	100	300	✓	4,22 €
GPL10-100/NY	10	100	300	✓	4,25 €
GPL12-100/NY	12	100	300	✓	4,28 €
GPL15-100/NY	15	100	300	✓	4,33 €
GPL20-100/NY	20	100	300	✓	4,37 €
GPL25-100/NY	25	100	300	✓	4,45 €
GPL30-100/NY	30	100	300	✓	4,58 €
GPL40-100/NY	40	100	300	✓	4,75 €

Dimensions in mm

Our other products



GE32

Spring toggle latch with connecting link, Standard



G0

Steel spur gear, Steel 20NCD2



PRF_ART

Articulated bracket for use with aluminium profile, Standard



T10_30_AL

T type timing pulley, Economy range - T10 aluminium



WFRM

Flanged polymer nut, Polymer (Iglidur®) - 1 thread



BVR

Adjustable screw stop, Steel



UCFL_SS

Stainless steel flanged bearing, Stainless steel



SCR

Suction cup threaded insert, Insert for suction cup - Socket screw



DCG

Suction cup, 2.5 bellows, silicon



CHAE3030PA

Square decorative screwed hinges, Polyamide



CHAE4080PA

 
Symmetrical decorative screwed hinge, Polyamide



BFDdII


Locking pin for bushes, Nickel-plated steel

Complementary products



GPLss

 Brush, stainless steel




GPLac

Brush, steel



GPLbr

Brush, brass

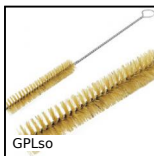

GPLso

Brush, silk