

Nylon brush

GPLNY

For mechanical and soft cleaning

- **Deburring brushes for soft materials**

- **Materials:**




Twisted galvanised steel

Nylon covered

Applications

- Gentle cleaning of hollow containers
(tubes, bottles, holes)

- Gentle cleaning of hard-to-reach areas

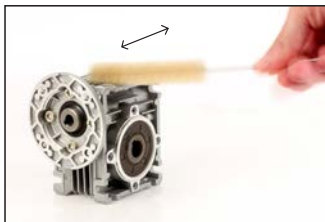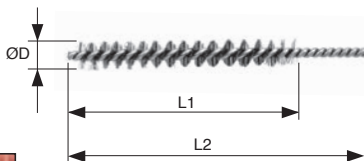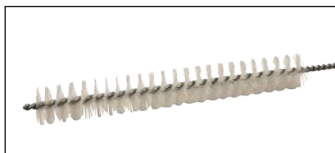

Cleaning the cooling fins of a gearbox

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL4-100/NY	4	100	300	✓	6,37 €
GPL6-100/NY	6	100	300	✓	4,19 €
GPL8-100/NY	8	100	300	✓	4,22 €
GPL10-100/NY	10	100	300	✓	4,25 €
GPL12-100/NY	12	100	300	✓	4,28 €
GPL15-100/NY	15	100	300	✓	4,33 €
GPL20-100/NY	20	100	300	✓	4,37 €
GPL25-100/NY	25	100	300	✓	4,45 €
GPL30-100/NY	30	100	300	✓	4,58 €
GPL40-100/NY	40	100	300	✓	4,75 €

Dimensions in mm

Our other products



DFG

Flat suction cup,
silicon



HSS

Shoulder screw
ISO7379, Hardened
Steel class 12.9



PTRSS

Idler chain sprocket,
For hostile
environments



E60B

Right angle helical
reducers, from 4.50 to
24 Nm



SH1

Parallel axis helical
gear, Steel 20NCD2



SH2

Parallel axis helical
gear, Machined plastic
(delrin)



EMS

Stainless steel knurled
thumb nut, Knurled



CABma

Swaging sleeve for
fitting cable, To crimp
a wire rope



MEB

Moulded plastic bevel
gear (nylon), 1:1



GMC_GMK_BR

Guiding profile clamp,
Flat or rounded



ERT

 
Sliding nut, For T slot



HFL


One way needle
bearing, Needle
bearing

Complementary products



GPLss

 Brush, stainless steel




GPLac

Brush, steel



GPLbr

Brush, brass

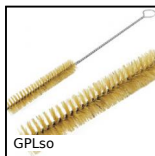

GPLso

Brush, silk