

- Brushes for the cleaning and removal of dust

- Materials:




- Twisted galvanised steel
- Natural silk covering

Application

- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas

Advantage

- Anti-static

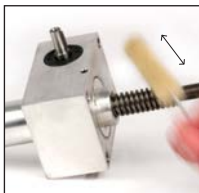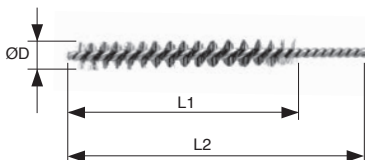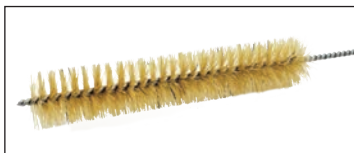

Cleaning of hard-to-reach areas

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | Brush diameter ØD | Brush length L1 | Total length L2 | Stock* | Price each 1 to 9 |
|--------------|-------------------|-----------------|-----------------|--------|-------------------|
| GPL15-100/SO | 15 | 80 | 300 | ✓ | 7,00 € |
| GPL20-100/SO | 20 | 80 | 300 | - | 8,27 € |
| GPL25-100/SO | 25 | 80 | 300 | ✓ | 7,38 € |

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



GBMf

Flanged leadscrew nut, Flanged nut - Multiple starts



ZG4

Plastic spur gear, Machined plastic (delrin)



 
E60B

Right angle helical reducers, from 4.50 to 24 Nm



GARDLL

Mounting sleeve for lock pin, Nickel-plated steel or Stainless steel



BLHM60

Right angled gearbox, double output shafts, up to 70 Nm



YG1

HEAVY DUTY spur gear, Steel 35NCD6



PCS62

Chain sprocket - steel, 15.875 (DIN 10B-1)



DPAR_DKON

Conical elasto buffer, Steel



LRRss

Latch, Spring loaded latch - stainless steel



SLBWSS

Indexing plunger, weldable, Weldable -



ES

 
Simple support base (bipod), Plastic



GBS


Nut for ballscrew, Flanged ballscrew nut

Complementary products



GPLss

 Brush, stainless steel




GPLac

Brush, steel



GPLbr

 Brush, brass



GPLny

Brush, nylon