

Deburring and stripping stainless steel

GPLSS


- Stainless steel deburring brushes

- Materials:

- Twisted galvanised steel
- Stainless steel covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

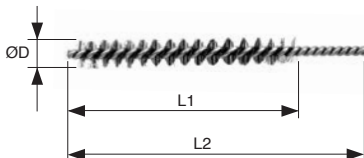

Deburring a gear bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Overall length L2	Stock*	Price each 1 to 9
GPL5-100/SS	5	100	300	✓	10,03 €
GPL8-100/SS	8	100	300	✓	8,58 €
GPL10-100/SS	10	100	300	✓	7,84 €
GPL12-100/SS	12	100	300	✓	7,84 €
GPL15-100/SS	15	100	300	✓	7,94 €
GPL20-100/SS	20	100	300	✓	8,22 €
GPL25-100/SS	25	100	300	✓	8,29 €

Dimensions in mm

Fax **0 825 88 6000**
Service 0,15 €/min
+ prix appel

Our other products



RESC
Retractable castor for aluminium profile, Retractable castor



RMSA
Adjustable shock-absorber, Adjustable



SH1
Parallel axis helical gear, Machined plastic (delrin)



ADL_F
Female eye bolt conforms to DIN582, Steel



PRES
Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



BLHB30
Right angled gearbox, bored shafts, up to 4.4 Nm



KITdog
24V DC motorisation kit, Worm and wheel



E30
Right angle helical reducers, from 1.50 to 9 Nm



HTD5M_09
HTD Heavy duty timing pulley, HTD5 Steel



RlMple
Locking castor, with mounting plate




PSG2
Spur gear - precision range, Case hardened steel 20NCD2



CM
Tools Hygienic Usit® and Hygienic Design®, Combination spanner

 
Complementary products



Brush, steel



 Brush, brass



Brush, nylon



Brush, silk