

Deburring and stripping stainless steel

GPLSS


- Stainless steel deburring brushes

- Materials:

- Twisted galvanised steel
- Stainless steel covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

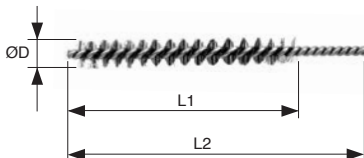

Deburring a gear bore

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | Brush diameter ØD | Brush length L1 | Overall length L2 | Stock* | Price each 1 to 9 |
|--------------|-------------------|-----------------|-------------------|--------|-------------------|
| GPL5-100/SS | 5 | 100 | 300 | ✓ | 10,03 € |
| GPL8-100/SS | 8 | 100 | 300 | ✓ | 8,58 € |
| GPL10-100/SS | 10 | 100 | 300 | ✓ | 7,84 € |
| GPL12-100/SS | 12 | 100 | 300 | ✓ | 7,84 € |
| GPL15-100/SS | 15 | 100 | 300 | ✓ | 7,94 € |
| GPL20-100/SS | 20 | 100 | 300 | ✓ | 8,22 € |
| GPL25-100/SS | 25 | 100 | 300 | ✓ | 8,29 € |

Dimensions in mm

Fax **0 825 88 6000**
Service 0,15 €/min
+ prix appel

Our other products



CFS

Miniature cam follower, Miniature



PAT123

Pressed stainless steel articulating foot
Ø123, Ø 123



TOC

Short swivel head,
Short



VTSM

Ball head screws
Hygienic Design®,
Stainless steel



PW_PWG3

Worm - precision range, Stainless steel



AT5-25ECO

AT type timing pulley,
Economy range - AT5 aluminium



SVG

Adjustable latch clamp with strike plate, Stroke from 106,7mm to 121...



BOX-TOR-C

Box set of Nitrile O-rings in nitrile, 3.00 x 1.50mm to 30.20 x 3.00



VLBG

Lifting ring, Rotating



AC

Strike for toggle latch,
15mm



EIM

 
Stainless steel U bolt,
Stainless steel



UFX

Uneflex® elastic coupling, range

Complementary products




GPLac

Brush, steel




GPLbr

 Brush, brass



GPLny

Brush, nylon

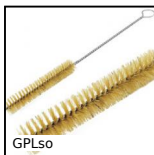

GPLso

Brush, silk