

Deburring and stripping stainless steel

GPLSS


- Stainless steel deburring brushes

- Materials:

- Twisted galvanised steel
- Stainless steel covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

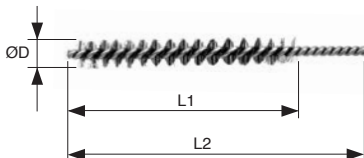

Deburring a gear bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Overall length L2	Stock*	Price each 1 to 9
GPL5-100/SS	5	100	300	✓	10,03 €
GPL8-100/SS	8	100	300	✓	8,58 €
GPL10-100/SS	10	100	300	✓	7,84 €
GPL12-100/SS	12	100	300	✓	7,84 €
GPL15-100/SS	15	100	300	✓	7,94 €
GPL20-100/SS	20	100	300	✓	8,22 €
GPL25-100/SS	25	100	300	✓	8,29 €

Dimensions in mm

0 825 88 6000
Service 0,15 €/min
+ prix appel

Our other products



R203

Die spring ISO10243,
Light



PR85

Articulated foot Ø83,
Ø 83



MSP3815

Masterplate®
glueable insert
rectangular,
rectangular with



AC

Strike for toggle latch,
15mm



NPTF20

Fixed tube carrier,
Fixed Ø10 to Ø14



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab



VPPTss

Stainless steel
handwheel with
handle, Stainless steel
304



 
RPC

Wheel, Polyamide




PTGP

Tensioner pulley, For
flat belts



RPPM

 RPP type belt per
metre, RPP5 Steel



PRF-GPA


Guide for aluminium
profile, Parallel rails



STRIP1000

Sealing brush strip,
1m length

 Complementary products




GPLac

Brush, steel



GPLbr

 Brush, brass



GPLny

Brush, nylon



GPLso

Brush, silk