



Belt tensioner


For applications in hostile environments

GTCss

- **Belt tensioner**
 - Sealing caps not fitted
 - Integrated bearings
 - Max working temp : 70°C
 - Materials :
 - Nut, screw and spacer : Galvanised steel
 - Roller : Polyamide



Corrosion resistant materials

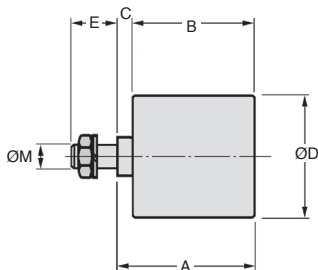

DISCOUNTS

Qty	1+	3+	5+
Disc.	List	-10%	On request

Part number	A	B	C	ØD	E	ØM	Arm size	Max speed (rpm)	Stock*	Price each 1 to 2
GTC-2/SS	38	35	3	30	13	M8	BTE2	8000	✓	35,56 €
GTC-3/4/SS	51	45	6	40	16	M10	BTE3-BTE4	8000	✓	49,07 €
GTC-5/SS	67,5	60	7,5	60	21,5	M12	BTE5	6000	✓	100,23 €

*Depending on availability - Dimensions in mm

Our other products



G1

Steel spur gear, Steel 20NCD2



CAP882

Flexible slat top chain acetal, Large range 882



ACL-PR

Joining plate for aluminium profile, Right angled connection



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



RLR

Roll-Ring® chain tensioner, Roll-Ring® Self-adjusting



T5P_T10P

Connecting plate for T type timing belts, T10



BLHM20

Right angled gearbox, double output shafts, up to 1.77 Nm



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools



P40

Worm and wheel gear reducer, up to 18 Nm



GMK17_BR

Clamp for guiding profile, Rounded only - single



BPFL

Sheet steel flanged bearing for light loads, Sheet steel



BPM

Slotted spring plunger with ball tip, Stainless steel 303

Complementary products



BTE

Universal tension arm, For standard applications