



Belt tensioner


For applications in hostile environments

GTCss

- **Belt tensioner**
 - Sealing caps not fitted
 - Integrated bearings
 - Max working temp : 70°C
 - Materials :
 - Nut, screw and spacer : Galvanised steel
 - Roller : Polyamide



Corrosion resistant materials

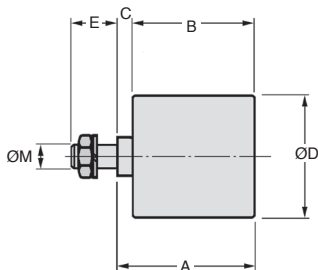

DISCOUNTS

Qty	1+	3+	5+
Disc.	List -10%	On request	

Part number	A	B	C	ØD	E	ØM	Arm size	Max speed (rpm)	Stock*	Price each 1 to 2
GTC-2/SS	38	35	3	30	13	M8	BTE2	8000	✓	35,56 €
GTC-3/4/SS	51	45	6	40	16	M10	BTE3-BTE4	8000	✓	49,07 €
GTC-5/SS	67,5	60	7,5	60	21,5	M12	BTE5	6000	✓	100,23 €

*Depending on availability - Dimensions in mm

Our other products



BLH20

Right angled gearbox,
from 0.53 to 1.77



CHB

Worm and wheel gear
reducer, up to 41 Nm



SERB

Universal latch key,
Universal latch key



D-PAR_SS

Stainless steel elasto
mount, stainless steel



ZBRA

Machined plastic
bevel gear, 1:1




GE_ES

Spherical bushing,
Steel / steel




HLC24

 Right angle spiro
bevel gearbox, Up to
78Nm



GMC

 Flat profile - Round
guide, Flat profile -
round guide



RIMtce

Locking castor, with
central hole



ACLBMC

Detector support for
aluminium profile,



PTA50

Articulated levelling
foot, pressed base



SH4

Parallel axis helical
gear, Steel 20NCD2

Complementary products



BTE

Universal tension arm,
For standard
applications