



Belt tensioner


For applications in hostile environments

GTCss

- **Belt tensioner**
 - Sealing caps not fitted
 - Integrated bearings
 - Max working temp : 70°C
 - Materials :
 - Nut, screw and spacer : Galvanised steel
 - Roller : Polyamide



Corrosion resistant materials

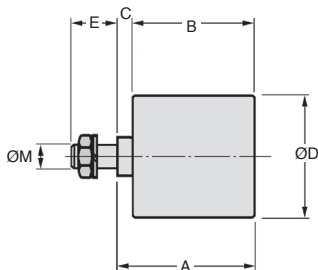

DISCOUNTS

Qty	1+	3+	5+
Disc.	List -10%	On request	

Part number	A	B	C	ØD	E	ØM	Arm size	Max speed (rpm)	Stock*	Price each 1 to 2
GTC-2/SS	38	35	3	30	13	M8	BTE2	8000	✓	35,56 €
GTC-3/4/SS	51	45	6	40	16	M10	BTE3-BTE4	8000	✓	49,07 €
GTC-5/SS	67,5	60	7,5	60	21,5	M12	BTE5	6000	✓	100,23 €

*Depending on availability - Dimensions in mm

 
Our other products



PPJ
Indexing plunger with flange, With horizontal mounting flange and pu...



CHTRP
Single and dual output gearboxes, Up to 87,3Nm



CDRs
Retaining cable for ball pin, Retaining cable



FF30
Offset spur gear reducer, from 21.50 to 83 Nm



gt64r
Rotating bent lever with spring, Increased fitting tolerances



UFX
Spare tyre UNEFLEX® coupling, range



PSG15
Spur gear - precision range, Case hardened steel 20NCD2




PRES7HR
Manual workbench press, Force up to 700kg



RAGb
Cylindrical brush track, For gentle conveying and



 CQA30
Accessory for adjustment slide-system, 30



QNJ
Single row cylindrical roller bearing, Single flange on inner ring



SUPCC
Self-centering clamping hub steel, With lock nut

Complementary products



BTE
Universal tension arm, For standard applications