

Steel


Module
0.4

- Power transferred through 90°
- Teeth are angled at 45° to the right
- Pressure angle 20°
- Material: Steel 20NCD2



Info.

Important: A helical gear with a 45° RH angle meshes with a second identically angled gear.

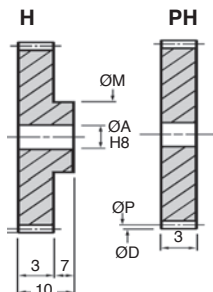

Torque and power indication		
For 50 teeth at 1000 rpm		
	20NCD2 Z10CNF18.09	20NCD2 hardened
Nm	0,056	0,375
kW	0,006	0,039

DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List	-12%	-25%	On request	

Part number	Z Teeth	ØP PCD	ØD Outside	ØM Boss	ØA Bore	Price each 1 to 5	
						H	PH
H0.4-10	10	5,66	6,46	6,46	2	16,56 €	
H0.4-12	12	6,79	7,59	7,59	2	16,56 €	
H0.4-15	15	8,49	9,29	9,29	2	16,30 €	
H0.4-16	16	9,05	9,85	9,85	2	16,35 €	
H0.4-20	20	11,31	12,11	8,00	3	16,66 €	
H0.4-25	25	14,14	14,94	8,00	3	17,10 €	
H0.4-26	26	14,71	15,51	8,00	3	17,20 €	
H0.4-30	30	16,97	17,77	12,00	3	17,90 €	
H0.4-35	35	19,80	20,60	12,00	3	18,73 €	
H0.4-36	36	20,36	21,16	12,00	3	18,85 €	
H0.4-40	40	22,63	23,43	12,00	4	19,60 €	
H0.4-46	46	26,02	26,82	12,00	4	21,22 €	
H0.4-50	50	28,28	29,08	12,00	4	21,47 €	
H0.4-55	55	31,11	31,91	12,00	4	21,76 €	
H0.4-56	56	31,68	32,48	12,00	4	21,76 €	
H0.4-60	60	33,94	34,74	12,00	4	22,31 €	
H0.4-65	65	36,77	37,57	12,00	4	23,43 €	
H0.4-68	68	38,47	39,27	12,00	4	23,81 €	
H0.4-70	70	39,60	40,40	12,00	4	24,32 €	
H0.4-75	75	42,43	43,23	12,00	4	25,47 €	
H0.4-80	80	45,25	46,05	12,00	5	25,65 €	
H0.4-86	86	48,65	49,45	12,00	5	26,60 €	
H0.4-90	90	50,91	51,71	12,00	5	30,07 €	
H0.4-100	100	56,57	57,37	12,00	5	32,76 €	
H0.4-120	120	67,88	68,68	12,00	5	38,28 €	

On request

↓ Gears available up to this size ↓			
H0.4-246	246	Dimensions: contact us	on request

Dimensions in mm

Our other products



VAP

Magnetic stud with central hole, With central hole



KH

Linear bearing, Light



H2

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



SMS

Spiral bevel gear, 1:1



CHTRB

Single and dual
output gearboxes, Up
to 4,7 Nm



CHAFR

Adjustable friction
hinges, Friction



BSM

Spring plunger with
internal hexagonal
socket, stainless steel
303 b...



T5_11

T type timing pulley,
T5 aluminium



UFX

Uneflex® elastic
coupling, range



PMC150_M16

Anti-vibration
machine mount,



BTC_M

End cap with threaded
insert for square tube,



HG6

Steel spur gear, Steel
20NCD2

Complementary products