


Steel

Module
0.4

- Power transferred through 90°
- Teeth are angled at 45° to the right
- Pressure angle 20°
- Material: Steel 20NCD2

Info.

Important: A helical gear with a 45° RH angle meshes with a second identically angled gear.

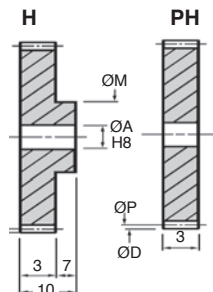

Torque and power indication		
For 50 teeth at 1000 rpm		
	20NCD2 Z10CNF18.09	20NCD2 hardened
Nm	0,056	0,375
kW	0,006	0,039

DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List	-12%	-25%	On request	

Part number	Z Teeth	ØP PCD	ØD Outside	ØM Boss	ØA Bore	Price each 1 to 5	H	PH
H0.4-10	10	5,66	6,46	6,46	2	16,56 €		
H0.4-12	12	6,79	7,59	7,59	2	16,56 €		
H0.4-15	15	8,49	9,29	9,29	2	16,30 €		
H0.4-16	16	9,05	9,85	9,85	2	16,35 €		
H0.4-20	20	11,31	12,11	8,00	3	16,66 €		
H0.4-25	25	14,14	14,94	8,00	3	17,10 €		
H0.4-26	26	14,71	15,51	8,00	3	17,20 €		
H0.4-30	30	16,97	17,77	12,00	3	17,90 €		
H0.4-35	35	19,80	20,60	12,00	3	18,73 €		
H0.4-36	36	20,36	21,16	12,00	3	18,85 €		
H0.4-40	40	22,63	23,43	12,00	4	19,60 €		
H0.4-46	46	26,02	26,82	12,00	4	21,22 €		
H0.4-50	50	28,28	29,08	12,00	4	21,47 €		
H0.4-55	55	31,11	31,91	12,00	4	21,76 €		
H0.4-56	56	31,68	32,48	12,00	4	21,76 €		
H0.4-60	60	33,94	34,74	12,00	4	22,31 €		
H0.4-65	65	36,77	37,57	12,00	4	23,43 €		
H0.4-68	68	38,47	39,27	12,00	4	23,81 €		
H0.4-70	70	39,60	40,40	12,00	4	24,32 €		
H0.4-75	75	42,43	43,23	12,00	4	25,47 €		
H0.4-80	80	45,25	46,05	12,00	5	25,65 €		
H0.4-86	86	48,65	49,45	12,00	5	26,60 €		
H0.4-90	90	50,91	51,71	12,00	5	30,07 €		
H0.4-100	100	56,57	57,37	12,00	5	32,76 €		
H0.4-120	120	67,88	68,68	12,00	5	38,28 €		

On request

↓ Gears available up to this size ↓			
H0.4-246	246	Dimensions: contact us	on request

Dimensions in mm

Our other products



MDB_MTB
Moulded plastic bevel gear (nylon), 3:1




PSG25
Spur gear - precision range, Case hardened steel 20NCD2



AT5-16ECO
AT type timing pulley, Economy range - AT5 aluminium



SEV
Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel

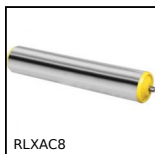

RLXAC8
Free roller, Steel



BLH40
Right angled gearbox, from 3 to 10.30 Nm



SVG
Adjustable latch clamp with strike plate, Stroke from 106,7mm to 121...



CHAPAMss
Weld-on hinge with flat end, Stainless steel or Aluminium



GPB
Threaded spherical knob, With brass



M0
Worm and wheel set, Hardened steel



OPFL_OPPM
Numerical counter accessories,



CFES
Eccentric cam follower, Eccentric

Complementary products