


Steel

Module
0.7

- Power transferred through 90°
- Teeth are angled at 45° to the right
- Pressure angle 20°
- Material: Steel 20NCD2

Info.

Important: A helical gear with a 45° RH angle meshes with a second identically angled gear.

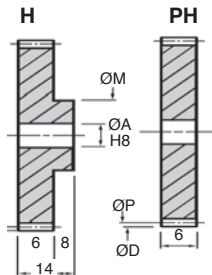

Torque and power indication		
For 50 teeth at 1000 rpm		
	20NCD2 Z10CNF18.09	20NCD2 hardened
Nm	0.272	1.791
kW	0.028	0.188

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	ØP PCD	ØD Outside	ØM Boss	ØA Bore	Price each 1 to 5	H	PH
H0.7-9	9	8,91	10,31	10,31	4	19,68 €		
H0.7-10	10	9,90	11,30	11,30	4	20,55 €		
H0.7-15	15	14,85	16,25	12,00	5	23,13 €		
H0.7-16	16	15,84	17,24	12,00	5	23,39 €		
H0.7-18	18	17,82	19,22	12,00	5	24,07 €		
H0.7-20	20	19,80	21,20	12,00	5	24,58 €		
H0.7-25	25	24,75	26,15	12,00	5	25,06 €		
H0.7-26	26	25,74	27,14	12,00	5	25,11 €		
H0.7-30	30	29,70	31,10	16,00	6	25,50 €		
H0.7-35	35	34,65	36,05	16,00	6	26,19 €		
H0.7-36	36	35,64	37,04	16,00	6	26,27 €		
H0.7-40	40	39,60	41,00	16,00	6	26,92 €		
H0.7-46	46	45,54	46,94	16,00	6	28,10 €		
H0.7-50	50	49,50	50,90	16,00	6	29,42 €		
H0.7-55	55	54,45	55,85	16,00	6	30,44 €		
H0.7-56	56	55,44	56,84	16,00	6	30,44 €		
H0.7-60	60	59,40	60,80	16,00	6	32,40 €		
H0.7-66	66	65,34	66,74	16,00	6	38,45 €		
H0.7-70	70	69,30	70,70	20,00	8	40,76 €		
H0.7-75	75	74,25	75,65	20,00	8	46,41 €		
H0.7-80	80	79,20	80,60	20,00	8	55,72 €		
H0.7-90	90	89,10	90,50	20,00	8	58,27 €		
H0.7-100	100	98,99	100,39	20,00	10	68,85 €		
H0.7-120	120	118,97	120,19	20,00	10	79,27 €		
↓ Gears available up to this size ↓								
H0.7-140	140	138,59	139,99	30,00	12	On request		

 
On request

Dimensions in mm


Our other products



BIMSS
Indexing plunger mini,
miniature - Stainless
steel



LAT1
1A motorised linear
actuator, 1 ampere

 

PRL
Wear strip for slat top
chain, L profile to be
clipped



T5M T10M
T type timing belt per
metre, T5 Steel cored
polyurethane



DOMI50
Connecting kits, XY
linking kit



HSE-HSB
Hexagonal spacer,
Steel




YG2
HEAVY DUTY spur
gear, Steel 35NCD6



V3RA_PTR
3-spoked handwheel
with foldable handle,
Polyamide



 PLM-20SC
Threaded cylindrical
magnet, With



MAT
Drawn ground round
bar, 100C6 steel bar



BKGS
Backlash free
coupling Gerwah®,



FGWA
End support, With
base

Complementary products