


Steel

Module  
**0.7**

- Power transferred through 90°
- Teeth are angled at 45° to the right
- Pressure angle 20°
- Material: Steel 20NCD2

**Info.**

**Important:** A helical gear with a 45° RH angle meshes with a second identically angled gear.

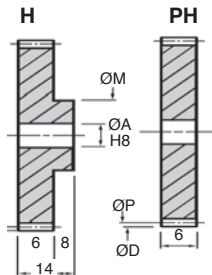

Torque and power indication		
For 50 teeth at 1000 rpm		
	20NCD2 Z10CNF18.09	20NCD2 hardened
Nm	0.272	1.791
kW	0.028	0.188

**DISCOUNTS**

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	ØP PCD	ØD Outside	ØM Boss	ØA Bore	Price each 1 to 5	H	PH
H0.7-9	9	8,91	10,31	10,31	4	19,68 €		
H0.7-10	10	9,90	11,30	11,30	4	20,55 €		
H0.7-15	15	14,85	16,25	12,00	5	23,13 €		
H0.7-16	16	15,84	17,24	12,00	5	23,39 €		
H0.7-18	18	17,82	19,22	12,00	5	24,07 €		
H0.7-20	20	19,80	21,20	12,00	5	24,58 €		
H0.7-25	25	24,75	26,15	12,00	5	25,06 €		
H0.7-26	26	25,74	27,14	12,00	5	25,11 €		
H0.7-30	30	29,70	31,10	16,00	6	25,50 €		
H0.7-35	35	34,65	36,05	16,00	6	26,19 €		
H0.7-36	36	35,64	37,04	16,00	6	26,27 €		
H0.7-40	40	39,60	41,00	16,00	6	26,92 €		
H0.7-46	46	45,54	46,94	16,00	6	28,10 €		
H0.7-50	50	49,50	50,90	16,00	6	29,42 €		
H0.7-55	55	54,45	55,85	16,00	6	30,44 €		
H0.7-56	56	55,44	56,84	16,00	6	30,44 €		
H0.7-60	60	59,40	60,80	16,00	6	32,40 €		
H0.7-66	66	65,34	66,74	16,00	6	38,45 €		
H0.7-70	70	69,30	70,70	20,00	8	40,76 €		
H0.7-75	75	74,25	75,65	20,00	8	46,41 €		
H0.7-80	80	79,20	80,60	20,00	8	55,72 €		
H0.7-90	90	89,10	90,50	20,00	8	58,27 €		
H0.7-100	100	98,99	100,39	20,00	10	68,85 €		
H0.7-120	120	118,97	120,19	20,00	10	79,27 €		
↓ <b>Gears available up to this size</b> ↓								
H0.7-140	140	138,59	139,99	30,00	12	On request		

Dimensions in mm

On request

## Our other products



ACLEPP

Right angled bracket for aluminium profile, 2 holes



PF30

Worm and wheel gear reducer, up to 8.80 Nm



S20

Short housing for open linear bearing, Opened - slim



PRF\_VTM

Hammerhead screw, Hammerhead screw




BOXINS300

Box set of self tapping inserts, Boxed set - For hard materials




PTGP

 Tensioner pulley, For flat belts



RIMtce

 Locking castor, with central hole



SHTP

Drylin® Linear table, Economy range



GMK17\_BR

Clamp for guiding profile, Rounded only



ACL-PLAngle

Joining plate for aluminium profile,



PSG25

Spur gear - precision range, Stainless steel



Q1

Self-aligning radial ball bearing, Steel

Complementary products