

Slotted flat headed shoulder screw **DIN 923**



HAS

Steel

- Fixes to a frame and allows rotation around the shoulder
- Conforms to DIN 923
- Material:
Burnished steel, resistance class 5.8

Accessory

- Used with HAR captive C washer (tome 1 p.214)

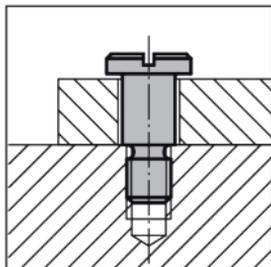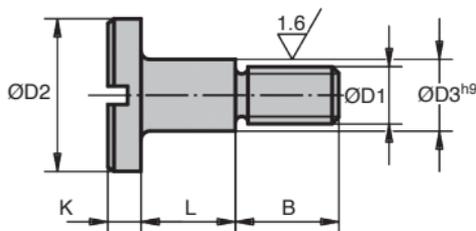

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request



Part number	ØD1	ØD2	ØD3	L	B	K	Weight (g)	For captive washer	Stock*	Price each 1 to 5
HAS6-8-10	M6	13	8,9	10 +0,07/+0,15	9	3,1	9	HAR9	✓	2,73 €
HAS8-10-12	M8	16	10,9	12 +0,1/+0,2	11	3,8	17	HAR11	✓	3,09 €
HAS10-13-16	M10	20	13,0	16 +0,1/+0,2	13,5	4,6	33	-	-	4,14 €

*Depending on availability - Dimensions in mm

- Allows a shaft to be held with simple pivoting action
- Conforms to DIN 6371
- Material:
Burnished steel

Accessory

- Used with HAS shoulder screw (acc DIN 923) (**tome 1** p.215)

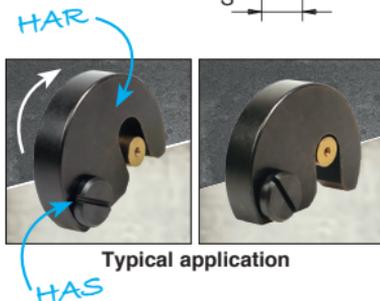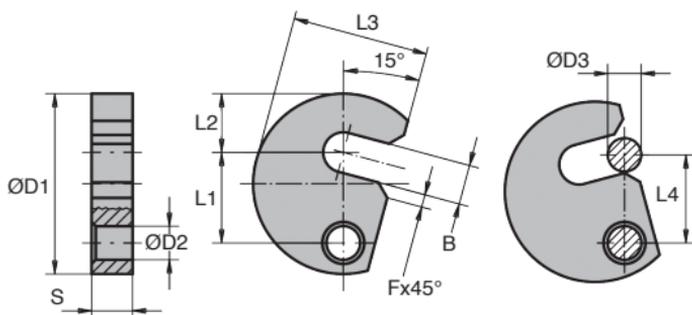

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	B	ØD1	ØD2	ØD3	F	L1	L2	L3	L4	S	Weight (g)	Stock*	Price each 1 to 5
												✓	
HAR9-38	7,5	38	9	6	3	19,6	11	29	19	9,8	0,061	✓	27,33 €
HAR9-43	9,5	43	9	8	3	21,6	14	32,5	21	9,8	0,076	-	28,67 €
HAR9-48	11,5	48	9	10	3	23,6	17	36,5	23	9,8	0,09	✓	32,17 €
HAR11-61	13,5	61	11	12	3	29,6	22	45	29	11,8	0,18	✓	40,23 €
HAR11-65	15,5	65	11	14	3	31,6	23	49	31	11,8	0,2	-	43,15 €
HAR11-68	17,5	68	11	16	3	33,6	25	50	33	11,8	0,21	-	45,58 €
HAR11-74	21,5	74	11	20	4	36,6	28	55	36	11,8	0,23	-	58,19 €

*Depending on availability - Dimensions in mm