



- Conforms to DIN 916
- Material:  
Stainless steel 302/304 - A2
- Working temperature up to +430°C
- Sold by the packet

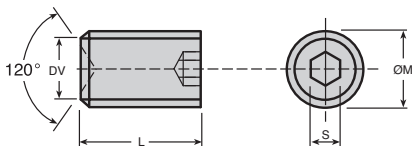

### Designer's Note

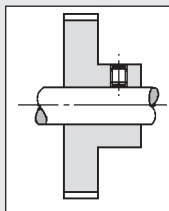

Bore or shaft diameter		Screw size
from Ø	to Ø (included)	ØT
Ø4	- Ø6	M3
Ø6	- Ø8	M3
Ø8	- Ø10	M3
Ø10	Ø12	M4
Ø12	- Ø17	M5
Ø17	- Ø22	M6
Ø22	- Ø30	M8
Ø30	- Ø44	M10
Ø44	- Ø58	M12

### DISCOUNTS

N° packets	1+	2+	4+
Disc.	List	-20%	On request

Part number	Thread		Length			Qty. per packet	Stock*	Price per packet
	ØM	Pitch	L	DV	S			
HC2-3/SS/B	M2	0,40	3	1,0	0,9	200	✓	23,13 €
HC2-4/SS/B	M2	0,40	4	1,0	0,9	200	✓	20,92 €
HC2-5/SS/B	M2	0,40	5	1,0	0,9	200	✓	21,70 €
HC2-6/SS/B	M2	0,40	6	1,0	0,9	200	✓	21,13 €
HC2-10/SS/B	M2	0,40	10	1,0	0,9	500	✓	36,94 €
HC2.5-5/SS/B	M2,5	0,45	5	1,2	1,3	200	✓	22,63 €
HC2.5-8/SS/B	M2,5	0,45	8	1,2	1,3	200	-	24,20 €
HC2.5-10/SS/B	M2,5	0,45	10	1,2	1,3	200	-	24,77 €

\*Depending on availability - Dimensions in mm

Part number	Thread		Length			Qty. per packet	Stock*	Price per packet
	ØM	Pitch	L	DV	S			
HC3-4/SS/B	M3	0,50	4	1,4	1,5	500	✓	14,28 €
HC3-5/SS/B	M3	0,50	5	1,4	1,5	500	✓	11,59 €
HC3-6/SS/B	M3	0,50	6	1,4	1,5	500	✓	11,78 €
HC3-8/SS/B	M3	0,50	8	1,4	1,5	500	✓	14,81 €
HC3-10/SS/B	M3	0,50	10	1,4	1,5	500	✓	15,88 €
HC3-12/SS/B	M3	0,50	12	1,4	1,5	500	-	17,30 €
HC3-16/SS/B	M3	0,50	16	1,4	1,5	500	-	21,59 €
HC3-20/SS/B	M3	0,50	20	1,4	1,5	500	✓	30,34 €
HC4-4/SS/B	M4	0,70	4	2,0	2,0	500	✓	7,67 €
HC4-5/SS/B	M4	0,70	5	2,0	2,0	500	✓	6,95 €
HC4-6/SS/B	M4	0,70	6	2,0	2,0	500	✓	7,67 €
HC4-8/SS/B	M4	0,70	8	2,0	2,0	500	-	8,02 €
HC4-10/SS/B	M4	0,70	10	2,0	2,0	500	✓	10,52 €
HC4-12/SS/B	M4	0,70	12	2,0	2,0	500	-	13,73 €
HC4-16/SS/B	M4	0,70	16	2,0	2,0	500	-	13,73 €
HC4-20/SS/B	M4	0,70	20	2,0	2,0	500	✓	19,09 €
HC5-5/SS/B	M5	0,80	5	2,5	2,5	500	✓	9,63 €
HC5-6/SS/B	M5	0,80	6	2,5	2,5	500	✓	8,74 €
HC5-8/SS/B	M5	0,80	8	2,5	2,5	500	✓	8,74 €
HC5-10/SS/B	M5	0,80	10	2,5	2,5	500	✓	11,42 €
HC5-12/SS/B	M5	0,80	12	2,5	2,5	500	✓	14,28 €
HC5-16/SS/B	M5	0,80	16	2,5	2,5	500	-	18,02 €
HC5-20/SS/B	M5	0,80	20	2,5	2,5	500	✓	21,77 €
HC5-25/SS/B	M5	0,80	25	2,5	2,5	200	-	12,63 €
HC5-30/SS/B	M5	0,80	30	2,5	2,5	200	✓	18,49 €
HC6-6/SS/B	M6	1,00	6	3,0	3,0	500	✓	16,95 €
HC6-8/SS/B	M6	1,00	8	3,0	3,0	500	✓	14,99 €
HC6-10/SS/B	M6	1,00	10	3,0	3,0	500	✓	28,01 €
HC6-12/SS/B	M6	1,00	12	3,0	3,0	500	✓	24,09 €
HC6-16/SS/B	M6	1,00	16	3,0	3,0	500	-	31,05 €
HC6-20/SS/B	M6	1,00	20	3,0	3,0	500	✓	39,80 €
HC6-25/SS/B	M6	1,00	25	3,0	3,0	200	✓	20,27 €
HC6-30/SS/B	M6	1,00	30	3,0	3,0	200	✓	26,48 €
HC6-35/SS/B	M6	1,00	35	3,0	3,0	200	-	24,13 €
HC6-40/SS/B	M6	1,00	40	3,0	3,0	200	✓	30,63 €
HC8-16/SS/B	M8	1,25	16	5,0	4,0	200	✓	18,42 €
HC8-20/SS/B	M8	1,25	20	5,0	4,0	200	✓	21,63 €
HC8-25/SS/B	M8	1,25	25	5,0	4,0	200	-	26,41 €
HC8-30/SS/B	M8	1,25	30	5,0	4,0	200	✓	45,05 €
HC8-40/SS/B	M8	1,25	40	5,0	4,0	200	-	49,19 €
HC10-10/SS/B	M10	1,50	10	6,0	5,0	100	-	11,28 €
HC10-16/SS/B	M10	1,50	16	6,0	5,0	100	-	17,42 €
HC10-20/SS/B	M10	1,50	20	6,0	5,0	100	✓	22,56 €
HC10-25/SS/B	M10	1,50	25	6,0	5,0	100	-	21,59 €
HC10-30/SS/B	M10	1,50	30	6,0	5,0	100	-	26,94 €
HC10-40/SS/B	M10	1,50	40	6,0	5,0	100	-	38,41 €
HC10-50/SS/B	M10	1,50	50	6,0	5,0	100	-	57,69 €

\*Depending on availability - Dimensions in mm

## Our other products



GG1

Ground spur gear,  
Heat treated steel



PSG15S

Spur gear - precision  
range, Stainless steel  
303



SSDB

Stainless steel bevel  
gear, 2:1



SERB

Cam latch, Cam latch



PRF\_BR

Clamp for aluminium  
profile, Clamp for  
profile




BAGSS

Stainless steel  
Clamping collar,  
Stainless steel



CNA-CNG

Right angled  
mounting plate, Right  
angled mounting  
plate for clevis

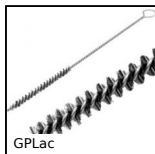

GPLac

Brush, steel



 
DPAR\_DKON

Progressive stop,  
Steel



BOXbeta

Box of assorted hitch  
pins, Boxed set - hitch



T2

T type timing belt,  
T2.5 Steel cored



ZBconique

Machined plastic  
bevel gear, 1:1

## Complementary products



NTMbr

Set screw brass tip,  
Brass-point



NTMdl

Set screw delrin tip,  
Delrin-point