



- Conforms to DIN 916
- Material:  
Stainless steel 302/304 - A2
- Working temperature up to +430°C
- Sold by the packet

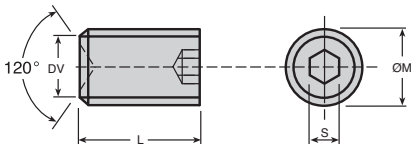

### Designer's Note

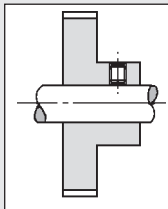

| Bore or shaft diameter |                 | Screw size |
|------------------------|-----------------|------------|
| from Ø                 | to Ø (included) | ØT         |
| Ø4                     | - Ø6            | M3         |
| Ø6                     | - Ø8            | M3         |
| Ø8                     | - Ø10           | M3         |
| Ø10                    | Ø12             | M4         |
| Ø12                    | - Ø17           | M5         |
| Ø17                    | - Ø22           | M6         |
| Ø22                    | - Ø30           | M8         |
| Ø30                    | - Ø44           | M10        |
| Ø44                    | - Ø58           | M12        |

### DISCOUNTS

| N° packets | 1+   | 2+   | 4+         |
|------------|------|------|------------|
| Disc.      | List | -20% | On request |

| Part number   | Thread |       | Length |     |     | Qty. per packet | Stock* | Price per packet |
|---------------|--------|-------|--------|-----|-----|-----------------|--------|------------------|
|               | ØM     | Pitch | L      | DV  | S   |                 |        |                  |
| HC2-3/SS/B    | M2     | 0,40  | 3      | 1,0 | 0,9 | 200             | ✓      | 23,13 €          |
| HC2-4/SS/B    | M2     | 0,40  | 4      | 1,0 | 0,9 | 200             | ✓      | 20,92 €          |
| HC2-5/SS/B    | M2     | 0,40  | 5      | 1,0 | 0,9 | 200             | ✓      | 21,70 €          |
| HC2-6/SS/B    | M2     | 0,40  | 6      | 1,0 | 0,9 | 200             | ✓      | 21,13 €          |
| HC2-10/SS/B   | M2     | 0,40  | 10     | 1,0 | 0,9 | 500             | ✓      | 36,94 €          |
| HC2.5-5/SS/B  | M2,5   | 0,45  | 5      | 1,2 | 1,3 | 200             | ✓      | 22,63 €          |
| HC2.5-8/SS/B  | M2,5   | 0,45  | 8      | 1,2 | 1,3 | 200             | -      | 24,20 €          |
| HC2.5-10/SS/B | M2,5   | 0,45  | 10     | 1,2 | 1,3 | 200             | -      | 24,77 €          |

\*Depending on availability - Dimensions in mm

| Part number  | Thread |       | Length |     |     | Qty. per packet | Stock* | Price per packet |
|--------------|--------|-------|--------|-----|-----|-----------------|--------|------------------|
|              | ØM     | Pitch | L      | DV  | S   |                 |        |                  |
| HC3-4/SS/B   | M3     | 0,50  | 4      | 1,4 | 1,5 | 500             | ✓      | 14,28 €          |
| HC3-5/SS/B   | M3     | 0,50  | 5      | 1,4 | 1,5 | 500             | ✓      | 11,59 €          |
| HC3-6/SS/B   | M3     | 0,50  | 6      | 1,4 | 1,5 | 500             | ✓      | 11,78 €          |
| HC3-8/SS/B   | M3     | 0,50  | 8      | 1,4 | 1,5 | 500             | ✓      | 14,81 €          |
| HC3-10/SS/B  | M3     | 0,50  | 10     | 1,4 | 1,5 | 500             | ✓      | 15,88 €          |
| HC3-12/SS/B  | M3     | 0,50  | 12     | 1,4 | 1,5 | 500             | -      | 17,30 €          |
| HC3-16/SS/B  | M3     | 0,50  | 16     | 1,4 | 1,5 | 500             | -      | 21,59 €          |
| HC3-20/SS/B  | M3     | 0,50  | 20     | 1,4 | 1,5 | 500             | ✓      | 30,34 €          |
| HC4-4/SS/B   | M4     | 0,70  | 4      | 2,0 | 2,0 | 500             | ✓      | 7,67 €           |
| HC4-5/SS/B   | M4     | 0,70  | 5      | 2,0 | 2,0 | 500             | ✓      | 6,95 €           |
| HC4-6/SS/B   | M4     | 0,70  | 6      | 2,0 | 2,0 | 500             | ✓      | 7,67 €           |
| HC4-8/SS/B   | M4     | 0,70  | 8      | 2,0 | 2,0 | 500             | -      | 8,02 €           |
| HC4-10/SS/B  | M4     | 0,70  | 10     | 2,0 | 2,0 | 500             | ✓      | 10,52 €          |
| HC4-12/SS/B  | M4     | 0,70  | 12     | 2,0 | 2,0 | 500             | -      | 13,73 €          |
| HC4-16/SS/B  | M4     | 0,70  | 16     | 2,0 | 2,0 | 500             | -      | 13,73 €          |
| HC4-20/SS/B  | M4     | 0,70  | 20     | 2,0 | 2,0 | 500             | ✓      | 19,09 €          |
| HC5-5/SS/B   | M5     | 0,80  | 5      | 2,5 | 2,5 | 500             | ✓      | 9,63 €           |
| HC5-6/SS/B   | M5     | 0,80  | 6      | 2,5 | 2,5 | 500             | ✓      | 8,74 €           |
| HC5-8/SS/B   | M5     | 0,80  | 8      | 2,5 | 2,5 | 500             | ✓      | 8,74 €           |
| HC5-10/SS/B  | M5     | 0,80  | 10     | 2,5 | 2,5 | 500             | ✓      | 11,42 €          |
| HC5-12/SS/B  | M5     | 0,80  | 12     | 2,5 | 2,5 | 500             | ✓      | 14,28 €          |
| HC5-16/SS/B  | M5     | 0,80  | 16     | 2,5 | 2,5 | 500             | -      | 18,02 €          |
| HC5-20/SS/B  | M5     | 0,80  | 20     | 2,5 | 2,5 | 500             | ✓      | 21,77 €          |
| HC5-25/SS/B  | M5     | 0,80  | 25     | 2,5 | 2,5 | 200             | -      | 12,63 €          |
| HC5-30/SS/B  | M5     | 0,80  | 30     | 2,5 | 2,5 | 200             | ✓      | 18,49 €          |
| HC6-6/SS/B   | M6     | 1,00  | 6      | 3,0 | 3,0 | 500             | ✓      | 16,95 €          |
| HC6-8/SS/B   | M6     | 1,00  | 8      | 3,0 | 3,0 | 500             | ✓      | 14,99 €          |
| HC6-10/SS/B  | M6     | 1,00  | 10     | 3,0 | 3,0 | 500             | ✓      | 28,01 €          |
| HC6-12/SS/B  | M6     | 1,00  | 12     | 3,0 | 3,0 | 500             | ✓      | 24,09 €          |
| HC6-16/SS/B  | M6     | 1,00  | 16     | 3,0 | 3,0 | 500             | -      | 31,05 €          |
| HC6-20/SS/B  | M6     | 1,00  | 20     | 3,0 | 3,0 | 500             | ✓      | 39,80 €          |
| HC6-25/SS/B  | M6     | 1,00  | 25     | 3,0 | 3,0 | 200             | ✓      | 20,27 €          |
| HC6-30/SS/B  | M6     | 1,00  | 30     | 3,0 | 3,0 | 200             | ✓      | 26,48 €          |
| HC6-35/SS/B  | M6     | 1,00  | 35     | 3,0 | 3,0 | 200             | -      | 24,13 €          |
| HC6-40/SS/B  | M6     | 1,00  | 40     | 3,0 | 3,0 | 200             | ✓      | 30,63 €          |
| HC8-16/SS/B  | M8     | 1,25  | 16     | 5,0 | 4,0 | 200             | ✓      | 18,42 €          |
| HC8-20/SS/B  | M8     | 1,25  | 20     | 5,0 | 4,0 | 200             | ✓      | 21,63 €          |
| HC8-25/SS/B  | M8     | 1,25  | 25     | 5,0 | 4,0 | 200             | -      | 26,41 €          |
| HC8-30/SS/B  | M8     | 1,25  | 30     | 5,0 | 4,0 | 200             | ✓      | 45,05 €          |
| HC8-40/SS/B  | M8     | 1,25  | 40     | 5,0 | 4,0 | 200             | -      | 49,19 €          |
| HC10-10/SS/B | M10    | 1,50  | 10     | 6,0 | 5,0 | 100             | -      | 11,28 €          |
| HC10-16/SS/B | M10    | 1,50  | 16     | 6,0 | 5,0 | 100             | -      | 17,42 €          |
| HC10-20/SS/B | M10    | 1,50  | 20     | 6,0 | 5,0 | 100             | ✓      | 22,56 €          |
| HC10-25/SS/B | M10    | 1,50  | 25     | 6,0 | 5,0 | 100             | -      | 21,59 €          |
| HC10-30/SS/B | M10    | 1,50  | 30     | 6,0 | 5,0 | 100             | -      | 26,94 €          |
| HC10-40/SS/B | M10    | 1,50  | 40     | 6,0 | 5,0 | 100             | -      | 38,41 €          |
| HC10-50/SS/B | M10    | 1,50  | 50     | 6,0 | 5,0 | 100             | -      | 57,69 €          |

\*Depending on availability - Dimensions in mm

## Our other products



CPAS

Stay with safety catch, Opens upward



HTD8M\_30

HTD Heavy duty timing pulley, HTD8 Steel



BLHT60

Right angled gearbox, from 26 to 70 Nm



MACss

Stainless steel carabiner, Stainless steel



PW\_PWG15

Wheel - precision range, Bronze



DOMI50

Accessories, Fixing kit



PO

Pull handle - Multi-sector, Tapped recessed insert



PRF4545\_P

Stripp Aluminium profile with extendable slot, 45 x 45 mm



METEB

Self-lubricating blanks, Bronze BP25



ASH

Hoist ring for welding, for straight lifts - for



COA-COG

Surface mounting plate, Surface



DOMI80

Connecting kits, XZ linking kit

## Complementary products



NTMbr

Set screw brass tip, Brass-point



NTMdl

Set screw delrin tip, Delrin-point