


Steel 20NCD2

Module 5.0

- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format

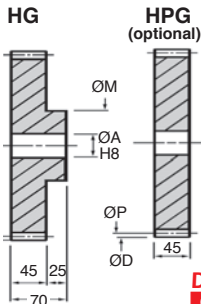

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2 Z10CNF18.09	hardened brass	fibre
Nm	294	1570	80	120
kW	30.80	165	8.30	12.60

DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%	List -5%	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 3 HG HPG
HG5-12	12	60,00	70,00	40	20	On request
HG5-14	14	70,00	80,00	50	25	76,14 €
HG5-15	15	75,00	85,00	50	25	On request
HG5-18	18	90,00	100,00	70	30	91,98 €
HG5-19	19	95,00	105,00	70	30	On request
HG5-20	20	100,00	110,00	80	30	152,85 €
HG5-21	21	105,00	115,00	80	30	On request
HG5-22	22	110,00	120,00	80	30	On request
HG5-23	23	115,00	125,00	85	30	114,00 €
HG5-24	24	120,00	130,00	85	30	On request
HG5-25	25	125,00	135,00	85	30	125,76 €
HG5-30	30	150,00	160,00	100	30	190,62 €
HG5-35	35	175,00	185,00	100	30	240,50 €
HG5-38	38	190,00	200,00	100	38	On request
HG5-40	40	200,00	210,00	150	38	On request
HG5-42	42	210,00	220,00	150	38	On request
HG5-45	45	225,00	235,00	150	38	On request
HG5-50	50	250,00	260,00	150	38	On request
HG5-52	52	260,00	270,00	150	38	On request
HG5-55	55	275,00	285,00	150	38	On request
Gears available up to this size						
HG5-115	115	575,00	585,00	Dimensions: contact us		On request

Dimensions in mm

On request

Our other products



ZG0

Plastic spur gear,
Machined plastic
(delrin)



SEH

Horizontal stirrup
toggle clamp,
Horizontal Latch
clamp - stainless steel



UTKpwrr

V shaped channel
UtiliTrak®, V rail



FBL4004_K7

Brush strip per meter
PA6 fibres Ø0.3 to
Ø0.5, Black polyamide
6 -...



SCH

Horizontal hook
toggle clamp,
Horizontal Hook
clamp - steel



GLT3-46A

Telescopic drawer
with damper,
Telescopic drawer with damper, Horizontal Latch clamp - stainless steel



VRM

Female swivelling
lifting rings, Female
swivelling



MFBS

Stainless steel flexible
bellows coupling,
Stainless steel - with
sealing



PRS30

Stainless steel
articulated foot Ø30,
Stainless steel articulated foot Ø30, Horizontal Latch clamp - stainless steel



ZG2

Plastic spur gear,
Machined plastic
(delrin)



AT5P_AT10P

Connecting plate for
AT type timing belts,
Connecting plate for AT type timing belts, Horizontal Latch clamp - stainless steel



SH1

Parallel axis helical
gear, Steel 20NCD2

Complementary products




ZHG5

Plastic spur gear,
Machined plastic
(delrin)



HG5-ECO

 Eco range Spur gear,
Steel C45



MR_MMR

Metric section rack,
Steel