

Steel 20NCD2



Module 5.0

- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2 Z10CNF18.09	hardened brass	fibre
Nm	294	1570	80	120
kW	30.80	165	8.30	12.60

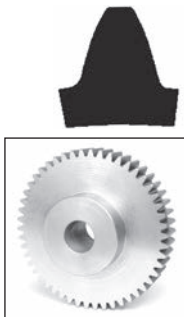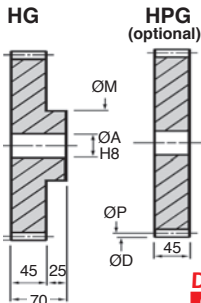

DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%	On request	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 3 HG HPG
HG5-12	12	60,00	70,00	40	20	On request
HG5-14	14	70,00	80,00	50	25	76,14 €
HG5-15	15	75,00	85,00	50	25	On request
HG5-18	18	90,00	100,00	70	30	91,98 €
HG5-19	19	95,00	105,00	70	30	On request
HG5-20	20	100,00	110,00	80	30	152,85 €
HG5-21	21	105,00	115,00	80	30	On request
HG5-22	22	110,00	120,00	80	30	On request
HG5-23	23	115,00	125,00	85	30	114,00 €
HG5-24	24	120,00	130,00	85	30	On request
HG5-25	25	125,00	135,00	85	30	125,76 €
HG5-30	30	150,00	160,00	100	30	190,62 €
HG5-35	35	175,00	185,00	100	30	240,50 €
HG5-38	38	190,00	200,00	100	38	On request
HG5-40	40	200,00	210,00	150	38	On request
HG5-42	42	210,00	220,00	150	38	On request
HG5-45	45	225,00	235,00	150	38	On request
HG5-50	50	250,00	260,00	150	38	On request
HG5-52	52	260,00	270,00	150	38	On request
HG5-55	55	275,00	285,00	150	38	On request
Gears available up to this size						
HG5-115	115	575,00	585,00	Dimensions: contact us		On request

Dimensions in mm

On request

Our other products



SBF

Sealed flange bearing unit for Food Industry, cover



WINGbr

Wing screw, hand tightened DIN316, Brass DIN 316



SVG

Adjustable latch clamp with strike plate, Stroke from 82mm to 92mm



VTHA

Magnetic screw with hexagonal head, Steel



SLH-M

Nut for toggle clamp, Round ended nut for SLH/SLV clamp



HTD5M_09

HTD Heavy duty timing pulley, HTD5 Aluminium



GB-RA

Brass spur gear, Brass CuZn39Pb3



P30

Worm and wheel gear reducer, up to 8.80 Nm



BAB

Hardened Stainless steel ball pin, Stainless steel



HSE-HSB

Hexagonal spacer, Steel



ERC

Quick fitting cable terminal, Fork



GAL48_OMNI

Omni-directional roller, Omni-directional

Complementary products




ZHG5

Plastic spur gear, Machined plastic (delrin)



HG5-ECO

 Eco range Spur gear, Steel C45



MR_MMR

Metric section rack, Steel