

Steel 20NCD2


Module 5.0



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format

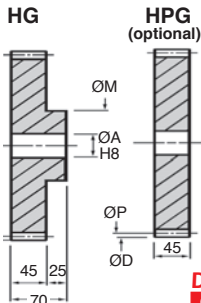

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2 Z10CNF18.09	hardened brass	fibre
Nm	294	1570	80	120
kW	30.80	165	8.30	12.60

DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%		On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 3 HG HPG
HG5-12	12	60,00	70,00	40	20	On request
HG5-14	14	70,00	80,00	50	25	76,14 €
HG5-15	15	75,00	85,00	50	25	On request
HG5-18	18	90,00	100,00	70	30	91,98 €
HG5-19	19	95,00	105,00	70	30	On request
HG5-20	20	100,00	110,00	80	30	152,85 €
HG5-21	21	105,00	115,00	80	30	On request
HG5-22	22	110,00	120,00	80	30	On request
HG5-23	23	115,00	125,00	85	30	114,00 €
HG5-24	24	120,00	130,00	85	30	On request
HG5-25	25	125,00	135,00	85	30	125,76 €
HG5-30	30	150,00	160,00	100	30	190,62 €
HG5-35	35	175,00	185,00	100	30	240,50 €
HG5-38	38	190,00	200,00	100	38	On request
HG5-40	40	200,00	210,00	150	38	On request
HG5-42	42	210,00	220,00	150	38	On request
HG5-45	45	225,00	235,00	150	38	On request
HG5-50	50	250,00	260,00	150	38	On request
HG5-52	52	260,00	270,00	150	38	On request
HG5-55	55	275,00	285,00	150	38	On request
Gears available up to this size						
HG5-115	115	575,00	585,00	Dimensions: contact us		On request

Dimensions in mm

On request

Our other products



RAG-12-M8
Roller guide accessory, Anchoring system



MHPGR
Arm with folding rotating handle,



PTMC
Telescopic furniture foot, square plate



AC144
Strike for toggle latch, 22mm



SRG
Adjustable latch clamp with strike plate, Stroke from 96mm to 121,7mm



SSHBRA
Stainless steel bevel gear, 1,5:1 2:1 3:1



G1
Steel spur gear, Steel 20NCD2



HLU
Spoked handwheel without handle, Aluminium



VTLB
Three-lobed knob, Thermoplastic / Brass or stainless steel



SCA_SS
Stainless steel flat cable clamp, Stainless steel



GSI
Stainless steel gas spring, Stainless steel



LINK64
Synchronous AC Motor and- gearbox , from 1.3 to 6Nm


Complementary products



ZHGS
Plastic spur gear, Machined plastic (delrin)



HG5-ECO
Eco range Spur gear, Steel C45

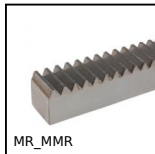

MR_MMR
Metric section rack, Steel