

Steel 20NCD2


Module 5.0



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format

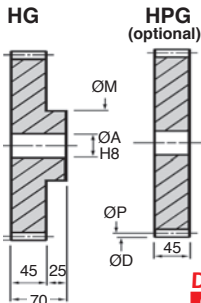

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2	brass	fibre
	Z10CNF18.09	hardened		
Nm	294	1570	80	120
kW	30.80	165	8.30	12.60

DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%		On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 3 HG HPG
HG5-12	12	60,00	70,00	40	20	On request
HG5-14	14	70,00	80,00	50	25	76,14 €
HG5-15	15	75,00	85,00	50	25	On request
HG5-18	18	90,00	100,00	70	30	91,98 €
HG5-19	19	95,00	105,00	70	30	On request
HG5-20	20	100,00	110,00	80	30	152,85 €
HG5-21	21	105,00	115,00	80	30	On request
HG5-22	22	110,00	120,00	80	30	On request
HG5-23	23	115,00	125,00	85	30	114,00 €
HG5-24	24	120,00	130,00	85	30	On request
HG5-25	25	125,00	135,00	85	30	125,76 €
HG5-30	30	150,00	160,00	100	30	190,62 €
HG5-35	35	175,00	185,00	100	30	240,50 €
HG5-38	38	190,00	200,00	100	38	On request
HG5-40	40	200,00	210,00	150	38	On request
HG5-42	42	210,00	220,00	150	38	On request
HG5-45	45	225,00	235,00	150	38	On request
HG5-50	50	250,00	260,00	150	38	On request
HG5-52	52	260,00	270,00	150	38	On request
HG5-55	55	275,00	285,00	150	38	On request
Gears available up to this size						
HG5-115	115	575,00	585,00	Dimensions: contact us		On request

Dimensions in mm

On request

Our other products



NPTF30
Fixed tube carrier,
Fixed Ø14 to Ø20



HLA19
Right angle spiro
bevel gearbox, Up to
43Nm



UCFL_PBT
Stainless
steel/Polymer flanged
bearing, Polymer and
stainless steel



BH01
Single housed
bearing, Bearing fitted
with adhesive



BOX-SHNA
Hexagonal nut -
DIN934, Box set of
steel nuts



NPTR10
Adjustable cross
clamp, Adjustable



ZBconique
Machined plastic
bevel gear, 1:1



SUPss
Self-centering
clamping hub
stainless steel,
Without locknut



NPTF20
Spacer for tube
carrier, Fixing
accessory Ø10 to Ø14



H02
Single needle roller
universal joint, Heavy
duty



HTD5M_25
HTD Heavy duty
timing pulley, HTD5
Aluminium



PRES
Manual workbench
press accessory for
PRES-3HR end
PRES-4HR, Micromet...


Complementary products



ZHG5
Plastic spur gear,
Machined plastic
(delrin)



 HG5-ECO
Eco range Spur gear,
Steel C45



MR_MMR
Metric section rack,
Steel