

Steel 20NCD2


Module 5.0



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

Option

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format

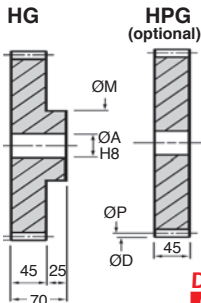

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2	brass	fibre
	Z10CNF18.09	hardened		
Nm	294	1570	80	120
kW	30.80	165	8.30	12.60

DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%		On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 3 HG HPG
HG5-12	12	60,00	70,00	40	20	On request
HG5-14	14	70,00	80,00	50	25	76,14 €
HG5-15	15	75,00	85,00	50	25	On request
HG5-18	18	90,00	100,00	70	30	91,98 €
HG5-19	19	95,00	105,00	70	30	On request
HG5-20	20	100,00	110,00	80	30	152,85 €
HG5-21	21	105,00	115,00	80	30	On request
HG5-22	22	110,00	120,00	80	30	On request
HG5-23	23	115,00	125,00	85	30	114,00 €
HG5-24	24	120,00	130,00	85	30	On request
HG5-25	25	125,00	135,00	85	30	125,76 €
HG5-30	30	150,00	160,00	100	30	190,62 €
HG5-35	35	175,00	185,00	100	30	240,50 €
HG5-38	38	190,00	200,00	100	38	On request
HG5-40	40	200,00	210,00	150	38	On request
HG5-42	42	210,00	220,00	150	38	On request
HG5-45	45	225,00	235,00	150	38	On request
HG5-50	50	250,00	260,00	150	38	On request
HG5-52	52	260,00	270,00	150	38	On request
HG5-55	55	275,00	285,00	150	38	On request
↓ Gears available up to this size ↓						
HG5-115	115	575,00	585,00	Dimensions: contact us		On request

Dimensions in mm

On request

Our other products



BOXbeta

Box of assorted hitch pins, Boxed set - hitch



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg



R203

Die spring ISO10243, Light



PRF_BP

Doorstop for aluminium profile, Swing door stop



FDSQ

Flexible drive shaft, Masterflex® Steel, with PVC casing



METEB

Self-lubricating blanks, Bronze BP25



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis



MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2



PDM_PDVB

Detectable plastic palm grip, by metal



PO

Pull handle - Multi-sector, Tapped



DGSA

Male rod ends, Steel / steel - Economy range

Complementary products




ZHG5

Plastic spur gear, Machined plastic (delrin)



HG5-ECO

 Eco range Spur gear, Steel C45



MR_MMR

Metric section rack, Steel