



- Economy range of gears
- Pressure angle 20°
- Material:
C45 steel UNI7845

Info

- Pilot bore information is given as a guide only and may vary between batches
- Gear should be finished to suit the application, **we are unable to offer this service**

Economy range

Supplied pre-bored

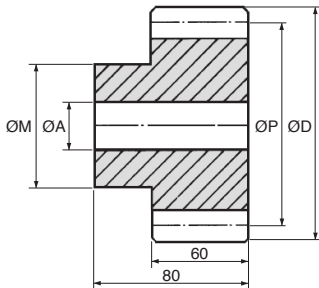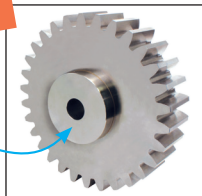

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore	Stock*	Price each 1 to 3
HG6-12/ECO	12	72	84	54	16	✓	42,10 €
HG6-13/ECO	13	78	90	60	16	✓	51,58 €
HG6-15/ECO	15	90	102	70	20	✓	59,88 €
HG6-16/ECO	16	96	108	75	20	✓	63,65 €
HG6-18/ECO	18	108	120	80	20	✓	83,46 €
HG6-20/ECO	20	120	132	90	20	✓	96,77 €
HG6-24/ECO	24	144	156	110	25	✓	142,32 €
HG6-25/ECO	25	150	162	110	25	✓	152,31 €

Dimensions in mm

Our other products



DOMI120
Accessories, Plate



LVT
Miniature motorised
actuator 2A, 2 amperes



VRSF
Male swivelling lifting
ring, Male swivelling



PO
Pull handle - Multi-
sector, Smooth hole



R204
Die spring ISO10243,
Average



BSM
Spring plunger with
internal hexagonal
socket, steel body,
plastic pin



CHA135
Screwed hinge, 135
degrees



NSU
Universal 90° support
clamp, Universal 90°
support clamp



CHAR6035
Spring hinge,
screwed/welded



CFUURSS
Cam follower stainless
steel, Standard -
stainless steel



PTA80ssEB
Articulated foot with
sheet metal base
Ø80, Articulated foot



P70
Worm and wheel gear
reducer, up to 164
Nm


Complementary products



HG6
Steel spur gear, Steel
20NCD2



 ZHG6
Plastic spur gear,
Machined plastic
(delrin)



MR_MMR
Metric section rack,
Steel



TRM
Spur round rack, Steel
- module 1-6