



- Economy range of gears
- Pressure angle 20°
- Material:
C45 steel UNI7845

Info

- Pilot bore information is given as a guide only and may vary between batches
- Gear should be finished to suit the application, **we are unable to offer this service**

Economy range

Supplied pre-bored

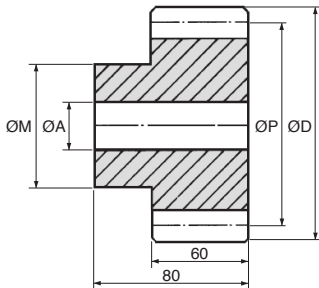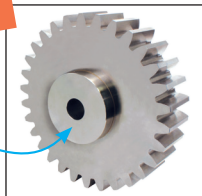

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore	Stock*	Price each 1 to 3
HG6-12/ECO	12	72	84	54	16	✓	42,10 €
HG6-13/ECO	13	78	90	60	16	✓	51,58 €
HG6-15/ECO	15	90	102	70	20	✓	59,88 €
HG6-16/ECO	16	96	108	75	20	✓	63,65 €
HG6-18/ECO	18	108	120	80	20	✓	83,46 €
HG6-20/ECO	20	120	132	90	20	✓	96,77 €
HG6-24/ECO	24	144	156	110	25	✓	142,32 €
HG6-25/ECO	25	150	162	110	25	✓	152,31 €

Dimensions in mm

Our other products



BOX-CS

Hose clamp, Box set of steel hose clamps



NAST

Cam follower without axial guide, With interior ring



WING

Manually tightened wing nut, Stainless steel DIN 314/315



MHX

Hexagonal threaded sleeve, Hexagonal - stainless steel



GE14

Toggle latches, With padlock-holder



CHAR

Spring hinge, screwed



EBM

Steel U bolt, Steel



BLHM40

Right angled gearbox, double output shafts, up to 10.3 Nm



BMM

Knurled knob - male, Knurled



OPFL_OPPM

Numerical counter accessories,



TPEf

Castor for aluminium profile, Fixed



IN1

Internal gear, Steel 20NCD2

Complementary products




HG6

Steel spur gear, Steel 20NCD2



ZHG6

 Plastic spur gear, Machined plastic (delrin)



MR_MMR

Metric section rack, Steel



TRM

Spur round rack, Steel - module 1-6