



- Economy range of gears
- Pressure angle 20°
- Material:
C45 steel UNI7845

Info

- Pilot bore information is given as a guide only and may vary between batches
- Gear should be finished to suit the application, **we are unable to offer this service**

Economy range

Supplied pre-bored

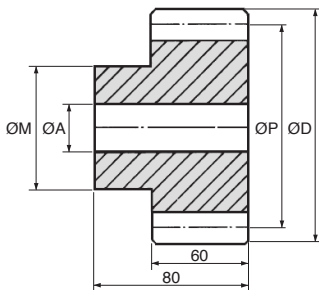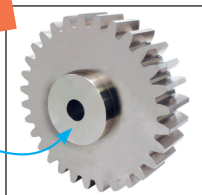

DISCOUNTS

Qty	1+	4+	10+
Disc. List	-5%	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore	Stock*	Price each 1 to 3
HG6-12/ECO	12	72	84	54	16	✓	42,10 €
HG6-13/ECO	13	78	90	60	16	✓	51,58 €
HG6-15/ECO	15	90	102	70	20	✓	59,88 €
HG6-16/ECO	16	96	108	75	20	✓	63,65 €
HG6-18/ECO	18	108	120	80	20	✓	83,46 €
HG6-20/ECO	20	120	132	90	20	✓	96,77 €
HG6-24/ECO	24	144	156	110	25	✓	142,32 €
HG6-25/ECO	25	150	162	110	25	✓	152,31 €

Dimensions in mm

Our other products



GG1

Ground spur gear,
Heat treated steel



HTD8M_50

HTD Heavy duty
timing pulley, HTD8
Cast



M0

Worm and wheel set,
Machined plastic
(delrin)



ZB

Shaft for linear
guides, Hardened
ground stainless steel



RIMtce

Locking castor, with
central hole



BLHT40

Right angled gearbox,
from 4 to 10.30 Nm



SBF

Sealed flange bearing
unit for Food Industry,
cover



FAD

Threaded swivel feet,
Swivel feet without
anti-slip plate



UCFL

Cast iron flanged
bearing, Cast iron



SLV

Vertical toggle clamp,
Vertical Lever Clamp -
stainless steel



BDPR

Holding arm, Rigid



OP3_14_06

Reducing sleeve for
OP indicators,
Reduction socket

Complementary products




HG6

Steel spur gear, Steel
20NCD2



ZHG6

 Plastic spur gear,
Machined plastic
(delrin)



MR_MMR

Metric section rack,
Steel



TRM

Spur round rack, Steel
- module 1-6