



- Economy range of gears
- Pressure angle 20°
- Material:  
C45 steel UNI7845

### Info

- Pilot bore information is given as a guide only and may vary between batches
- Gear should be finished to suit the application, **we are unable to offer this service**

**Economy range**

Supplied pre-bored

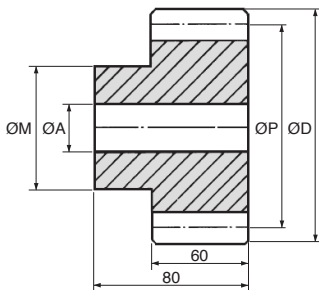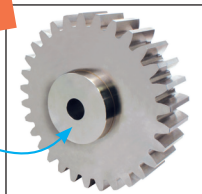

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Boss	ØA Pilot bore	Stock*	Price each 1 to 3
HG6-12/ECO	12	72	84	54	16	✓	42,10 €
HG6-13/ECO	13	78	90	60	16	✓	51,58 €
HG6-15/ECO	15	90	102	70	20	✓	59,88 €
HG6-16/ECO	16	96	108	75	20	✓	63,65 €
HG6-18/ECO	18	108	120	80	20	✓	83,46 €
HG6-20/ECO	20	120	132	90	20	✓	96,77 €
HG6-24/ECO	24	144	156	110	25	✓	142,32 €
HG6-25/ECO	25	150	162	110	25	✓	152,31 €

Dimensions in mm

## Our other products



SSG0  
Stainless steel spur gear, Stainless steel 304L



ACL-PL  
Joining plate for aluminium profile, Joint plate - 176x86 mm



PTA150  
Articulated levelling foot, pressed base Ø150, Ø 150



YG4  
HEAVY DUTY spur gear, Steel 35NCD6



CHMX\_CHMDX  
Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



MBF  
Threaded blocking clamp, Threaded locking clamp



CHAB  
Hinge with stop, Hinge



DIV\_SS  
Stainless steel locking bolt, With grip - Stainless steel



SVR15  
Screwjack with travelling nut, with moving nut



CHTRB  
Single and dual output gearboxes, Up to 16,5 Nm



RBN  
Wheel, Rubber tyre - Polypropylene rim



DOG319  
Motor-gearbox 12V and 24V DC, from 4 to 9 Nm


## Complementary products



HG6  
Steel spur gear, Steel 20NCD2



 ZHG6  
Plastic spur gear, Machined plastic (delrin)



MR\_MMR  
Metric section rack, Steel



TRM  
Spur round rack, Steel - module 1-6