

## Module 6.0



## Steel 20NCD2



- Precision class 9
- Pressure angle 20°
- Linear speed 300m/min

### Option

- Alternative number of teeth, a datasheet is available from [www.hpceurope.com](http://www.hpceurope.com) in PDF format

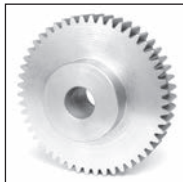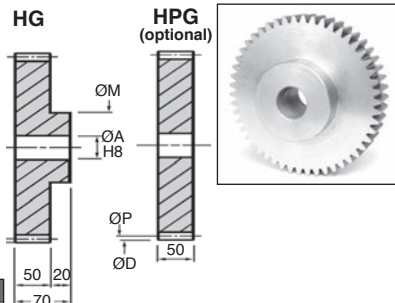

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2	20NCD2	brass	fibre
	Z10CNF18.09	hardened		
Nm	441	2350	120	180
kW	46	246	12.60	18.80

### DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%	On request	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 3	
						HG	HPG
HG6-12	12	72,00	84,00	50	25	On request	
HG6-14	14	84,00	96,00	60	25	83,80 €	
HG6-15	15	90,00	102,00	65	25	89,79 €	
HG6-18	18	108,00	120,00	80	30	107,74 €	
HG6-19	19	114,00	126,00	80	30	113,74 €	
HG6-20	20	120,00	132,00	90	30	119,71 €	
HG6-21	21	126,00	138,00	90	30	On request	
HG6-22	22	132,00	144,00	90	30	On request	
HG6-23	23	138,00	150,00	90	30	137,69 €	
HG6-24	24	144,00	156,00	90	30	On request	
HG6-25	25	150,00	162,00	90	30	149,67 €	
HG6-30	30	180,00	192,00	100	30	214,75 €	
HG6-31	31	186,00	198,00	100	30	On request	
HG6-32	32	192,00	204,00	120	38	On request	
HG6-35	35	210,00	222,00	120	38	309,76 €	
HG6-38	38	228,00	240,00	120	38	On request	
HG6-40	40	240,00	252,00	150	38	354,01 €	
HG6-41	41	246,00	258,00	150	38	On request	
HG6-42	42	252,00	264,00	150	38	On request	
HG6-44	44	264,00	276,00	150	38	On request	
↓ <b>Gears available up to this size</b> ↓							
HG6-95	95	570,00	582,00	Dimensions: contact us		On request	

On request

Dimensions in mm

## Our other products




PGMT  
Pull handle, Stainless steel



ACLERP  
Roller block for aluminium profile, Without guide rail



ZBRA  
Machined plastic bevel gear, 1:1

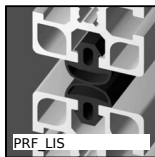

PRF LIS  
Door seal for aluminium profile, Black NBR



DOMI120  
Accessories, Fixing kit



SCA\_SS  
Stainless steel flat cable clamp, Stainless steel



UGH20  
H Type Guide units, For Ø20 actuators



GDR880  
Straight track for slat top chain, Ranges 880 and 881




VDSQ  
Sliding lock adjustment system, Sliding lock for square



YG2  
HEAVY DUTY spur gear, Steel 35NCD6



 MET  
Cylindrical sintered bronze bush, Self-lubricating sintered



NRR  
Adjustable support clamp, Adjustable support clamp


## Complementary products



ZHG6  
Plastic spur gear, Machined plastic (delrin)



 HG6-ECO  
Eco range Spur gear, Steel C45



MR\_MMR  
Metric section rack, Steel



TRM  
Spur round rack, Steel - module 1-6