


Module 8,0

C45 Steel

- Economical gear range
- Pressure angle 20°
- Material:
C45 steel UNI7845

Info.

- * Pre-bore information is given as a guide only and may vary between batches
- Gear should be finished to suit the application
- **We are unable to modify these gears**

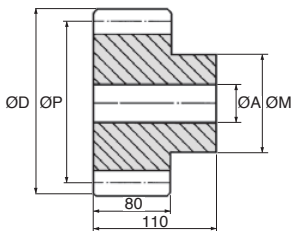

economic series

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Hub	ØA Pre-bore	Weight (kg)	Price each 1 to 3
HG8-15/ECO	15	120	136	90	25	8,2	90,91 €
HG8-18/ECO	18	144	160	100	25	11,7	119,76 €
HG8-20/ECO	20	160	176	120	30	14,6	134,96 €
HG8-24/ECO	24	192	208	150	30	21,7	178,68 €
HG8-25/ECO	25	200	216	150	30	23,3	191,37 €
HG8-28/ECO	28	224	240	170	30	29,5	218,95 €
HG8-30/ECO	30	240	256	190	30	34,4	242,79 €

All dimensions in mm

Our other products



NCT

Square tube connector, Fixed angle



PPF

Indexing plunger with flange, with drilled flange



MCL

Cylindrical threaded sleeve, Cylindrical - stainless steel



PGB

Accessory-holder for aluminium profile, Tool holder



RPP

Connecting plate for RPP type timing belts, RPP14



E15

Right angle helical reducers, from 0.40 to 2.53 Nm



EBM

Steel U bolt, Steel



NK17

Drylin®N miniature guiding system, Width 17 mm




GCA

Linch pin, Linch



SHTP

Drylin® Linear table, Economy range

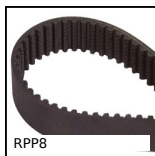

RPP8

RPP heavy duty timing belt, RPP8



PSEC

Security pull handle, Thermoplastic

Complementary products