


## Module 8,0

C45 Steel

- Economical gear range
- Pressure angle 20°
- Material:  
C45 steel UNI7845

### Info.

- \* Pre-bore information is given as a guide only and may vary between batches
- Gear should be finished to suit the application
- **We are unable to modify these gears**

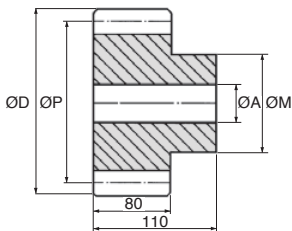

**economic series**

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	ØP PCD	ØD External	ØM Hub	ØA Pre-bore	Weight (kg)	Price each 1 to 3
HG8-15/ECO	15	120	136	90	25	8,2	90,91 €
HG8-18/ECO	18	144	160	100	25	11,7	119,76 €
HG8-20/ECO	20	160	176	120	30	14,6	134,96 €
HG8-24/ECO	24	192	208	150	30	21,7	178,68 €
HG8-25/ECO	25	200	216	150	30	23,3	191,37 €
HG8-28/ECO	28	224	240	170	30	29,5	218,95 €
HG8-30/ECO	30	240	256	190	30	34,4	242,79 €

All dimensions in mm

## Our other products



APBC  
Circular rod, Round rod



ADSR  
Backlash free coupling Gerwah®, from 12.5 to 525Nm



PRF4590  
Standard aluminium profile, 45 x 90 mm



TBD  
Manual leadscrew table with opposing threads, 2kg



MHXred  
Reducing sleeve male/female, Hexagonal - stainless steel



CLG1  
Moulded plastic spur gear, Moulded plastic (nylon)



DB  
Steel bevel gear, 2:1




HTD5M\_25  
HTD Heavy duty timing pulley, HTD5 Steel



PR85  
Articulated foot Ø83, Ø 83



 SNG  
Stainless/Polymer pillow block bearing,



TBL  
Mini leadscrew table with metric thread,



MPE  
Hexagonal spacer, Steel

Complementary products