

## Module 8,0



### C45 Steel

**Economy range**

- **Economical gear range**

- Pressure angle 20°

- Material:

C45 steel UNI7845



### Info.

- \* Pre-bore information is given as a guide only and may vary between batches

- Gear should be finished to suit the application

- **We are unable to modify these gears**

Supplied pre bored\*

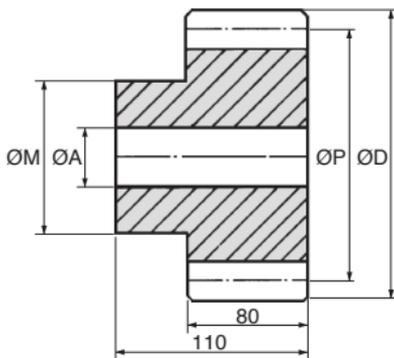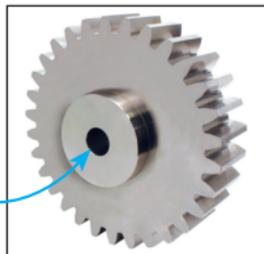

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-5%	On request

Part number	Z Teeth	$\varnothing P$ PCD	$\varnothing D$ External	$\varnothing M$ Hub	$\varnothing A$ Pre-bore	Weight (kg)	Price each 1 to 3
HG8-15/ECO	15	120	136	90	25	8,2	105,09 €
HG8-18/ECO	18	144	160	100	25	11,7	207,69 €
HG8-20/ECO	20	160	176	120	30	14,6	167,82 €
HG8-24/ECO	24	192	208	150	30	21,7	187,80 €
HG8-25/ECO	25	200	216	150	30	23,3	221,25 €
HG8-28/ECO	28	224	240	170	30	29,5	278,45 €
HG8-30/ECO	30	240	256	190	30	34,4	255,18 €

All dimensions in mm