

316 stainless steel


HLUMss

- Rotating handle (only)
- Similar to DIN98
- Material:  
1.4401 (316) stainless steel  
Polished finish

### Accessory

- See stainless steel spoked handwheel HLUSS

316 stainless steel

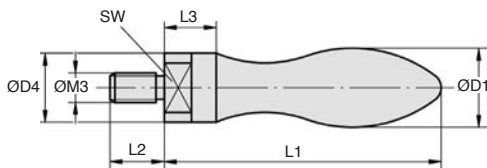

### DISCOUNTS

Qty	1+	3+	5+	10+
Disc. List	-5%	-10%	On request	

Part N°	ØD1	ØM3	ØD4	L1	L2	L3	SW	Price each
								1 to 2
HLUM-M6/SS	16	M6	11	57	12	11,45	8	16,06 €
HLUM-M8/SS	21	M8	14	71	14	13,45	10	20,32 €
HLUM-M10/SS	25	M10	16	86	16	14,45	11	26,09 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 €/min  
+ prix appel

## Our other products



PTA100

Articulated levelling foot, pressed base Ø100, Ø 100



CHM30

Worm and wheel gear reducer, up to 28 Nm



SSB

Stainless steel bevel gear, 1:1



BAG

Steel Clamping collar, Steel



PFM

Fixed levelling foot, Flanged plate



PLM-20SC

Threaded cylindrical magnet, With threaded hole



RPCtc

Swivel castor with central hole, Steel - Polyamide



BSM\_LOK

Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



CDGamme

Compression spring DIN2095, DIN 2095



GMK17\_BROSSE

Brush strip, Cone-shaped - brush



BLHB50


Right angled gearbox, bored shafts, up to 30 Nm



LRR22

Small dimension latch with locking system, Aluminium
 
## Complementary products



HLUss

Spoked handwheel, Stainless steel 316