

316 stainless steel


HLUMSS

- Rotating handle (only)
- Similar to DIN98
- Material:  
1.4401 (316) stainless steel  
Polished finish

### Accessory

- See stainless steel spoked handwheel HLUSS

316 stainless steel

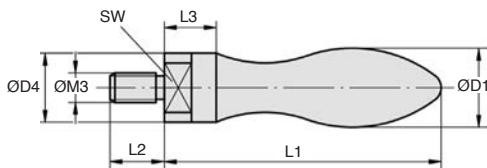

### DISCOUNTS

Qty	1+	3+	5+	10+
Disc. List	-5%	-10%	On request	

Part N°	ØD1	ØM3	ØD4	L1	L2	L3	SW	Price each
								1 to 2
HLUM-M6/SS	16	M6	11	57	12	11,45	8	16,06 €
HLUM-M8/SS	21	M8	14	71	14	13,45	10	20,32 €
HLUM-M10/SS	25	M10	16	86	16	14,45	11	26,09 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 €/min  
+ prix appel

## Our other products



PRF4590\_E

Bracket for aluminium profile, PRF4590



T10courroie

T type timing belt, T10 Steel cored polyurethane



P55

Worm and wheel gear reducer, up to 57 Nm



BPF1s5

Pressed stainless steel flange bearing, Stainless steel



 
RPC

Wheel, Polyamide



DB

Steel bevel gear, 2:1



PRT

Rotary table iglidur®, Iglidur®, aluminium and stainless steel



PSG15

Spur gear - precision range, Stainless steel 316



RPCpl

Swivel castor with plate, Steel -



SCH

Horizontal hook toggle clamp,



ACLERP

Roller block for aluminium profile,



PM2

Worm and wheel set, Hardened steel

## Complementary products



HLUss

Spoked handwheel, Stainless steel 316