

316 stainless steel


HLUMss

- Rotating handle (only)
- Similar to DIN98
- Material:
1.4401 (316) stainless steel
Polished finish

Accessory

- See stainless steel spoked handwheel HLUSS

316 stainless steel

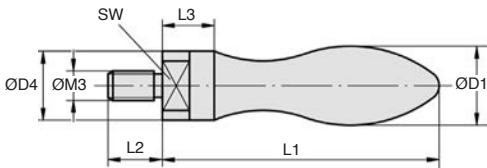

DISCOUNTS

Qty	1+	3+	5+	10+
Disc. List	-5%	-10%	On request	

Part N°	ØD1	ØM3	ØD4	L1	L2	L3	SW	Price each 1 to 2
HLUM-M6/SS	16	M6	11	57	12	11,45	8	16,06 €
HLUM-M8/SS	21	M8	14	71	14	13,45	10	20,32 €
HLUM-M10/SS	25	M10	16	86	16	14,45	11	26,09 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 €/min
+ prix appel

Our other products



BH01
Flange with bearing,
Bearing fitted with
adhesive



SH0
Parallel axis helical
gear, Machined plastic
(delrin)



SER69K
Quarter turn latch for
the food industry,
Stainless steel



M
Bellows cover,
Standard



SSDB
Stainless steel bevel
gear, 2:1



LPCM
Lever with cylindrical
handle, Black
Duroplast, steel lever



ABL100000
Antistatic brush, For
sensitive surfaces



TOC
Swivel head, Short




SFWR
Shaft end support,
Surface mounting



BABT
Ball pin, Hardened
stainless steel




 DOMI30
DOMILINE -
Adjustment slide,
Slide DOMILINE 30



VP
Small 6 lobe threaded
handle, Duroplast -
Steel

 Complementary products



HLUss
Hand wheel, Stainless
steel 316