

Spoked handwheel with revolving handle **Alu**

HLUT

Aluminium


- Handwheel with revolving handle
- Materials:
 - Wheel: aluminium
 - Handle: aluminium with steel axle
- Finish: edges machined and polished
- Keyway conforms to DIN6885-1

Advantages

- Light

Options

- Handwheel without handle **HLU**

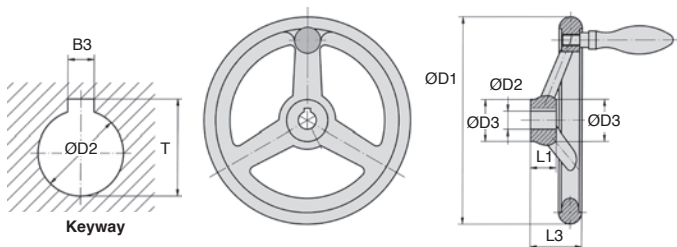

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number		Revolving hangle	ØD2		B3		T	Stock*	Stock*	Price each 1 to 5		
With keyway	Without keyway		ØD1 (H7)	ØD3	L1	L3 (P9)		With keyway	Without keyway	With keyway	Without keyway	
Avec 3 bras												
HLUT80-10K	HLUT80-10	Ø16xM6x54,5	80	10	24	16	29	3	11,4	✓	-	37,56 € 34,76 €
HLUT100-10K	HLUT100-10	Ø16xM6x54,5	100	10	26	17	33	3	11,4	✓	-	40,03 € 36,11 €
HLUT125-12K	HLUT125-12	Ø20xM8x67,0	125	12	28	18	36	4	13,8	✓	-	48,23 € 43,88 €
HLUT140-14K	HLUT140-14	Ø20xM8x67,0	140	14	30	19	39	5	16,3	✓	-	53,81 € 49,23 €
HLUT160-14K	HLUT160-14	Ø25xM10x83,0	160	14	32	20	40	5	16,3	✓	✓	63,01 € 59,75 €
HLUT180-16K	HLUT180-16	Ø25xM10x83,0	180	16	35	22	43	5	18,3	✓	✓	72,69 € 69,33 €
HLUT200-18K	HLUT200-18	Ø25xM10x83,0	200	18	38	24	45	6	20,8	✓	✓	81,57 € 77,57 €
Avec 5 bras												
HLUT250-22K	HLUT250-22	Ø32xM12x105,5	250	22	45	28	50	6	24,8	-	✓	122,40 € 117,86 €
HLUT315-26K	HLUT315-26	Ø32xM12x105,5	315	26	53	33	56	8	29,3	-	-	167,04 € 162,35 €
HLUT400-30K	HLUT400-30	Ø36xM16x117,0	400	30	65	38	63	8	33,3	-	-	276,20 € 270,91 €
HLUT500-34K	HLUT500-34	Ø36xM16x117,0	500	34	78	45	72	10	37,3	-	-	431,03 € 420,47 €

*Depending on availability - Dimensions in mm

Our other products




LQT

Mechanical catch,
Quick closing catch



MDB_MTB

Moulded plastic bevel
gear (nylon), 2:1

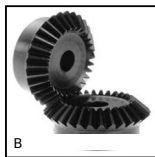

B

Steel bevel gear, 1:1



CDP

Flanged drill bushing,
Steel



BOX-SHNA

Hexagonal nut -
DIN934, Box set of
steel nuts



R204

Die spring ISO10243,
Average



SBF

Sealed flange bearing
unit for Food Industry,
cover



JSM

Cylindrical polymer
bush, Universal
polymer




IN1

Internal gear, Steel
20NCD2



CHAC4040NP

 Square hinge with
riveted pin, not
drilled, Square with
riveted pin,...



BLHM20

Right angled gearbox,
double output shafts,
up to 1.77 Nm



FBL6000_K1

Brush strip per meter
PA6 fibres Ø0.2 to
Ø0.3, Black polyamide
6 ...

Complementary products



HLU

Spoked handwheel
without handle,
Aluminium



HLUss

Spoked handwheel,
Stainless steel 316