

Spoked handwheel with revolving handle

HLUT

Aluminium


- Handwheel with revolving handle
- Materials:
 - Wheel: aluminium
 - Handle: aluminium with steel axle
- Finish: edges machined and polished
- Keyway conforms to DIN6885-1

Advantages

- Light

Options

- Handwheel without handle HLU

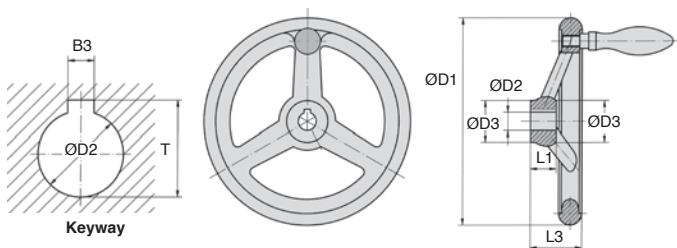

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number		Revolving handle	ØD2		B3		T	Stock*	Stock*	Price each 1 to 5		
With keyway	Without keyway		ØD1 (H7)	ØD3	L1	L3 (P9)		With keyway	Without keyway	With keyway	Without keyway	
Avec 3 bras												
HLUT80-10K	HLUT80-10	Ø16xM6x54,5	80	10	24	16	29	3	11,4	✓	-	37,56 € 34,76 €
HLUT100-10K	HLUT100-10	Ø16xM6x54,5	100	10	26	17	33	3	11,4	✓	-	40,03 € 36,11 €
HLUT125-12K	HLUT125-12	Ø20xM8x67,0	125	12	28	18	36	4	13,8	✓	-	48,23 € 43,88 €
HLUT140-14K	HLUT140-14	Ø20xM8x67,0	140	14	30	19	39	5	16,3	✓	-	53,81 € 49,23 €
HLUT160-14K	HLUT160-14	Ø25xM10x83,0	160	14	32	20	40	5	16,3	✓	✓	63,01 € 59,75 €
HLUT180-16K	HLUT180-16	Ø25xM10x83,0	180	16	35	22	43	5	18,3	✓	✓	72,69 € 69,33 €
HLUT200-18K	HLUT200-18	Ø25xM10x83,0	200	18	38	24	45	6	20,8	✓	✓	81,57 € 77,57 €
Avec 5 bras												
HLUT250-22K	HLUT250-22	Ø32xM12x105,5	250	22	45	28	50	6	24,8	-	✓	122,40 € 117,86 €
HLUT315-26K	HLUT315-26	Ø32xM12x105,5	315	26	53	33	56	8	29,3	-	-	167,04 € 162,35 €
HLUT400-30K	HLUT400-30	Ø36xM16x117,0	400	30	65	38	63	8	33,3	-	-	276,20 € 270,91 €
HLUT500-34K	HLUT500-34	Ø36xM16x117,0	500	34	78	45	72	10	37,3	-	-	431,03 € 420,47 €

*Depending on availability - Dimensions in mm

Our other products



DCG

Suction cup, 2.5 bellows, natural rubber



PM3

Worm and wheel set, Machined plastic (delrin)



 
ACLEPP

Right angled bracket for aluminium profile, 2 holes



HRV

V-rail guidance Simple Select® system, Rail with carriage



SLVHlok

Vertical toggle clamp, Vertical toggle clamp / horizontal foot



CLSCLP

Clevis components, short version, Steel - Short range



SDG_SS

Universal adjustable guide support bracket, Stainless steel



PSEC

Security pull handle, Thermoplastic



KB_OP

Open precision linear bearing, Precision -



CNA-CNG

Right angled mounting plate, Right



SSG1

Stainless steel spur gear, Stainless steel



SH3

 
Parallel axis helical gear, Steel 20NCD2

Complementary products



HLU

Spoked handwheel without handle, Aluminium



HLUss

Spoked handwheel, Stainless steel 316