




- Handwheel (only)
- Conforms to DIN950
- Versions with and without DIN6885-1 keyways
- Material:
Stainless steel 1.4401 (316)
Finish: turned and polished

316 stainless steel



Accessory

- HLUMSS rotating handle

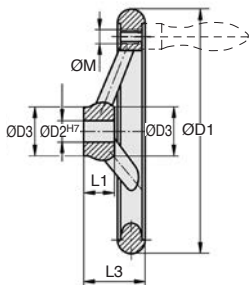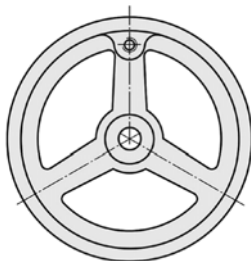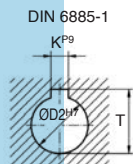

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L3	M	K	T	N° of spokes	Price each 1 to 2
No keyway										
HLU100-10/SS	100	10	26	17	33	M6	-	-	3	52,98 €
HLU125-12/SS	125	12	28	18	36	M8	-	-	3	75,98 €
HLU140-14/SS	140	14	30	19	39	M8	-	-	3	98,03 €
HLU160-16/SS	160	16	32	20	40	M10	-	-	3	112,01 €
HLU200-18/SS	200	18	38	24	45	M10	-	-	3	196,63 €
With keyway										
HLU100-10K/SS	100	10	26	17	33	M6	3	11,4	3	55,64 €
HLU125-12K/SS	125	12	28	18	36	M8	4	13,8	3	78,65 €
HLU140-14K/SS	140	14	30	19	39	M8	5	16,3	3	100,72 €
HLU160-16K/SS	160	16	32	20	40	M10	5	18,3	3	114,68 €
HLU200-18K/SS	200	18	38	24	45	M10	6	20,8	3	200,56 €

All dimensions in mm

Our other products



DB
Steel bevel gear, 2:1



H0
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



PRF-CHAR-POU
Tool holder for
aluminium profile,
Moveable tool holder



PRF_BV
Screw block, Panel
addition and fastening



PW_PWG05
Wheel - precision
range, Bronze



PM3
Worm and wheel set,
Hardened steel



AC
Strike for toggle latch,
15mm



PLC_PLT
Magnetic stud with
central hole, With
central hole



PSG15
Spur gear - precision
range, Case hardened



SCH
Horizontal hook
toggle clamp,



DOG258
Motor-gearbox 12V
and 24V DC, from 12



NIN
Self-locking nut, A2
Stainless steel

Complementary products



VPPTss
Stainless steel
handwheel with
handle, Stainless steel
304



HLUMss
Revolving handle for
handwheel, Stainless
steel 316



V3RA_PT
3-spoked handwheel
with handle,
Polyamide



V3RA
3-spoked handwheel
without handle,
Polyamide