




- Handwheel (only)
- Conforms to DIN950
- Versions with and without DIN6885-1 keyways
- Material:
Stainless steel 1.4401 (316)
Finish: turned and polished

316 stainless steel



Accessory

- HLUMSS rotating handle

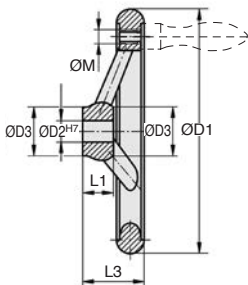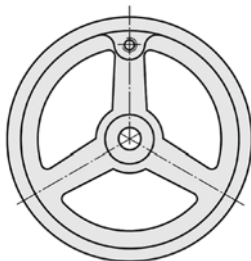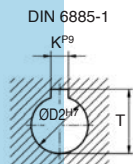

DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L3	M	K	T	N° of spokes	Price each 1 to 2
No keyway										
HLU100-10/SS	100	10	26	17	33	M6	-	-	3	52,98 €
HLU125-12/SS	125	12	28	18	36	M8	-	-	3	75,98 €
HLU140-14/SS	140	14	30	19	39	M8	-	-	3	98,03 €
HLU160-16/SS	160	16	32	20	40	M10	-	-	3	112,01 €
HLU200-18/SS	200	18	38	24	45	M10	-	-	3	196,63 €
With keyway										
HLU100-10K/SS	100	10	26	17	33	M6	3	11,4	3	55,64 €
HLU125-12K/SS	125	12	28	18	36	M8	4	13,8	3	78,65 €
HLU140-14K/SS	140	14	30	19	39	M8	5	16,3	3	100,72 €
HLU160-16K/SS	160	16	32	20	40	M10	5	18,3	3	114,68 €
HLU200-18K/SS	200	18	38	24	45	M10	6	20,8	3	200,56 €

All dimensions in mm

Our other products




GP
Spring loaded toggle latch, With padlock-holder



DOMI120
Domino 120 adjustable slide, Slide DOMILINE 120



 SEH
Horizontal stirrup toggle clamp, Horizontal Latch clamp - stainless ...



PRF-GPA
Guide for aluminium profile, Parallel rails



TBE16
Economic mini-table with trapezoidal leadscrew, 5kg



CHB
Double output shaft, For CHB gearbox



PRF4545_P
Stripp Aluminium profile with extendable slot, 45 x 45 mm



GBS
Nut for ballscrew, Flanged ballscrew nut



RVM14
Manual worm and wheel gearbox,



PSG15
Spur gear - precision range, Pre-hardened



SF_ZZ
Deep groove ball bearing, Stainless



GAL21
Conveyor wheel, Plastic

Complementary products



VPPTss
Stainless steel handwheel with handle, Stainless steel 304



HLUMss
Revolving handle for handwheel, Stainless steel 316



V3RA_PT
3-spoked handwheel with handle, Polyamide



V3RA
3-spoked handwheel without handle, Polyamide