




- Handwheel (only)
- Conforms to DIN950
- Versions with and without DIN6885-1 keyways
- Material:  
Stainless steel 1.4401 (316)  
Finish: turned and polished

316 stainless steel



### Accessory

- HLUMSS rotating handle

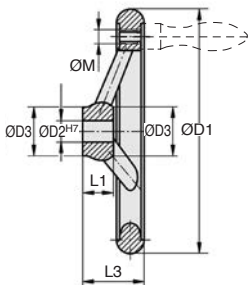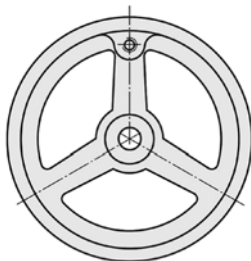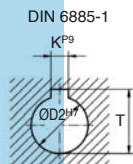

### DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-5%	-10%	On request

Part N°	ØD1	ØD2	ØD3	L1	L3	M	K	T	N° of spokes	Price each 1 to 2
<b>No keyway</b>										
HLU100-10/SS	100	10	26	17	33	M6	-	-	3	52,98 €
HLU125-12/SS	125	12	28	18	36	M8	-	-	3	75,98 €
HLU140-14/SS	140	14	30	19	39	M8	-	-	3	98,03 €
HLU160-16/SS	160	16	32	20	40	M10	-	-	3	112,01 €
HLU200-18/SS	200	18	38	24	45	M10	-	-	3	196,63 €
<b>With keyway</b>										
HLU100-10K/SS	100	10	26	17	33	M6	3	11,4	3	55,64 €
HLU125-12K/SS	125	12	28	18	36	M8	4	13,8	3	78,65 €
HLU140-14K/SS	140	14	30	19	39	M8	5	16,3	3	100,72 €
HLU160-16K/SS	160	16	32	20	40	M10	5	18,3	3	114,68 €
HLU200-18K/SS	200	18	38	24	45	M10	6	20,8	3	200,56 €

All dimensions in mm

## Our other products



PPD

Indexing plunger for sheets, For sheet metal



AC

Strike for toggle latch, 15mm



GBS

Nut for ballscrew, Flanged ballscrew nut



ZG0

Plastic spur gear, Machined plastic (delrin)



CHMR40

Worm and wheel gear reducer, up to 57 Nm



RT70

Self-centering locking Assembly, Medium/high torque



CABPVC

PVC covered galvanised steel cable, Galvanised steel with



WJRM

Drylin® W hybrid bearing block, Hybrid bearings



PRF\_CHA

Hinge for aluminium profile, Surface mounting hinge



CABtool

Fitting cable tools, Cutting tools



SLVHlok

Vertical toggle clamp, Vertical toggle clamp / horizontal foot



ATZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel

## Complementary products



VPPTss

Stainless steel handwheel with handle, Stainless steel 304



HLUMss

Revolving handle for handwheel, Stainless steel 316



V3RA\_PT

3-spoked handwheel with handle, Polyamide



V3RA

3-spoked handwheel without handle, Polyamide