


Hexagonal spacer

Sta Stock

HS

Stainless steel 303

- Female/female pillar
- Material:
stainless steel 303
- Sold by the packet

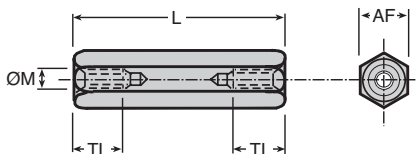

DISCOUNTS

| | | | | |
|------------|------|------|------|------------|
| N° packets | 1+ | 5+ | 20+ | 100+ |
| Discount | Prix | -20% | -30% | On request |

| Part number | Thread ØM | L | TL | AF | Qty per packet | Stock* | Price per packet |
|-------------|-----------|----|----|-----|----------------|--------|------------------|
| HS3-5/B | M3 | 5 | 5 | 5,5 | 20 | ✓ | 15,98 € |
| HS3-8/B | M3 | 8 | 8 | 5,5 | 20 | - | 16,92 € |
| HS3-10/B | M3 | 10 | 10 | 5,5 | 20 | ✓ | 17,25 € |
| HS3-15/B | M3 | 15 | 15 | 5,5 | 20 | ✓ | 21,03 € |
| HS3-20/B | M3 | 20 | 20 | 5,5 | 20 | ✓ | 26,19 € |
| HS3-25/B | M3 | 25 | 10 | 5,5 | 20 | - | 27,58 € |
| HS3-35/B | M3 | 35 | 10 | 5,5 | 20 | ✓ | 30,63 € |
| HS3-40/B | M3 | 40 | 10 | 5,5 | 20 | - | 31,39 € |
| HS4-5/B | M4 | 5 | 5 | 7,0 | 20 | - | 18,92 € |
| HS4-8/B | M4 | 8 | 8 | 7,0 | 20 | - | 20,64 € |
| HS4-10/B | M4 | 10 | 10 | 7,0 | 20 | ✓ | 22,59 € |
| HS4-12/B | M4 | 12 | 12 | 7,0 | 20 | ✓ | 24,22 € |
| HS4-15/B | M4 | 15 | 15 | 7,0 | 20 | - | 27,12 € |
| HS4-20/B | M4 | 20 | 20 | 7,0 | 20 | ✓ | 30,01 € |
| HS4-25/B | M4 | 25 | 10 | 7,0 | 20 | ✓ | 30,48 € |

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020


www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



 GE14
Toggle latches, With
padlock-holder



BETASS
Hitch pin, Hitch



BOXsap
Boxed set of spring
pins ISO8752, Boxed
set - Split ISO 8752



GE
Toggle latches,
Miniature



SRG
Adjustable latch
clamp with strike
plate, Stroke from
77,3mm to 83mm



SSB
Stainless steel bevel
gear, 1:1



SLH-M
Nut for toggle clamp,
Round ended nut for
SLH/SLV clamp



ABL100000
Antistatic brush, For
sensitive surfaces



TCSH
Automatic chain
tensioner, With



MSP23
Masterplate®
glueable insert Ø23,



PHG05
Parallel axis helical
gear - Precision range,



AC144
Strike for toggle latch,
22mm

Complementary products



MPS
Hexagonal spacer,
Stainless steel 303



MHX
Hexagonal threaded
sleeve, Hexagonal -
steel