


Hexagonal spacer

Ste Bra Stock

HSE
HSB

Steel or Brass

- Female/female pillar
- Material: Zn3-5BL steel zinc-plated by electrolysis or brass
- Sold by the packet

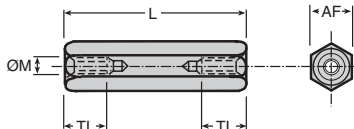

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number	Thread	ØM	L	TL	AF	Qty. per packet	Stock*		Price per packet	
							Steel	Brass	Steel	Brass
-	HSB2-5/B	M2	5	5	4	20	-	✓	-	3,64 €
-	HSB2-8/B	M2	8	8	4	20	-	✓	-	3,86 €
-	HSB2-10/B	M2	10	10	4	20	-	✓	-	4,09 €
-	HSB2-12/B	M2	12	12	4	20	-	✓	-	4,41 €
-	HSB2-15/B	M2	15	15	4	20	-	✓	-	5,78 €
-	HSB2-20/B	M2	20	20	4	20	-	✓	-	6,91 €
-	HSB2-25/B	M2	25	8	4	20	-	✓	-	10,40 €
-	HSB2-35/B	M2	35	8	4	20	-	-	-	13,99 €
-	HSB2-40/B	M2	40	8	4	20	-	✓	-	17,35 €
HSE2.5-5/B	HSB2.5-5/B	M2,5	5	5	5	20	✓	✓	5,97 €	3,41 €
-	HSB2.5-8/B	M2,5	8	8	5	20	-	✓	-	3,74 €
HSE2.5-10/B	HSB2.5-10/B	M2,5	10	10	5	20	✓	✓	6,91 €	4,67 €
-	HSB2.5-12/B	M2,5	12	12	5	20	-	✓	-	4,31 €
HSE2.5-15/B	-	M2,5	15	15	5	20	-	-	8,46 €	-
HSE2.5-20/B	HSB2.5-20/B	M2,5	20	20	5	20	-	-	10,46 €	6,84 €
HSE2.5-30/B	HSB2.5-30/B	M2,5	30	10	5	20	-	-	9,95 €	9,09 €
-	HSB3-5/B	M3	5	5	5	20	-	✓	-	3,20 €
HSE3-8/B	HSB3-8/B	M3	8	8	5	20	✓	✓	4,82 €	3,51 €
HSE3-10/B	HSB3-10/B	M3	10	10	5	20	✓	✓	4,38 €	3,74 €
HSE3-12/B	HSB3-12/B	M3	12	12	5	20	✓	✓	4,61 €	4,09 €
HSE3-15/B	HSB3-15/B	M3	15	15	5	20	✓	✓	5,78 €	4,41 €
HSE3-18/B	HSB3-18/B	M3	18	18	5	20	✓	-	6,37 €	4,98 €
HSE3-20/B	HSB3-20/B	M3	20	20	5	20	✓	✓	5,98 €	5,50 €
HSE3-25/B	HSB3-25/B	M3	25	10	5	20	✓	✓	5,91 €	6,33 €
HSE3-30/B	HSB3-30/B	M3	30	10	5	20	✓	-	7,07 €	7,23 €
HSE3-35/B	HSB3-35/B	M3	35	10	5	20	✓	✓	7,43 €	8,48 €
HSE3-40/B	HSB3-40/B	M3	40	10	5	20	✓	✓	6,66 €	10,49 €
HSE3-45/B	HSB3-45/B	M3	45	10	5	20	-	-	8,07 €	13,51 €
HSE3-50/B	HSB3-50/B	M3	50	10	5	20	-	-	13,04 €	12,87 €
HSE3-55/B	-	M3	55	10	5	20	-	-	13,61 €	-
HSE3-60/B	HSB3-60/B	M3	60	10	5	20	-	-	12,09 €	14,89 €
HSE3-70/B	-	M3	70	10	5	20	-	-	15,40 €	-

*Depending on availability - Dimensions in mm


DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number		Thread ØM	L	TL	AF	Qty. per packet	Stock*		Price per packet	
Steel	Brass						Steel	Brass	Steel	Brass
HSE4-8/B	HSB4-8/B	M4	8	8	7	20	✓	✓	5,71 €	5,12 €
HSE4-10/B	HSB4-10/B	M4	10	10	7	20	✓	-	5,87 €	5,43 €
HSE4-12/B	-	M4	12	12	7	20	✓	-	6,24 €	-
HSE4-15/B	HSB4-15/B	M4	15	15	7	20	✓	✓	6,81 €	6,98 €
HSE4-20/B	HSB4-20/B	M4	20	20	7	20	✓	✓	8,31 €	8,82 €
HSE4-25/B	HSB4-25/B	M4	25	10	7	20	✓	-	8,50 €	10,13 €
HSE4-30/B	HSB4-30/B	M4	30	10	7	20	✓	✓	9,19 €	11,85 €
HSE4-35/B	HSB4-35/B	M4	35	10	7	20	✓	-	9,79 €	14,09 €
HSE4-40/B	HSB4-40/B	M4	40	10	7	20	✓	✓	10,28 €	17,35 €
HSE4-45/B	HSB4-45/B	M4	45	10	7	20	✓	✓	10,57 €	19,32 €
HSE4-50/B	-	M4	50	10	7	20	✓	-	15,74 €	-
HSE4-55/B	-	M4	55	10	7	20	✓	-	16,48 €	-
HSE4-60/B	-	M4	60	10	7	20	✓	-	17,23 €	-
HSE4-70/B	-	M4	70	10	7	20	✓	-	18,79 €	-
HSE4-80/B	-	M4	80	10	7	20	✓	-	20,45 €	-
HSE5-10/B	HSB5-10/B	M5	10	10	8	20	-	-	6,61 €	6,45 €
HSE5-12/B	-	M5	12	12	8	20	✓	-	7,92 €	-
HSE5-15/B	HSB5-15/B	M5	15	15	8	20	✓	-	8,62 €	8,40 €
HSE5-20/B	HSB5-20/B	M5	20	20	8	20	✓	-	11,96 €	10,39 €
HSE5-25/B	HSB5-25/B	M5	25	10	8	20	✓	-	12,86 €	12,11 €
HSE5-30/B	HSB5-30/B	M5	30	10	8	20	✓	✓	13,89 €	14,09 €
HSE5-35/B	HSB5-35/B	M5	35	10	8	20	-	-	14,50 €	18,02 €
HSE5-40/B	-	M5	40	10	8	20	✓	-	15,28 €	-
HSE5-45/B	-	M5	45	10	8	20	-	-	16,27 €	-
HSE5-50/B	HSB5-50/B	M5	50	10	8	20	✓	-	17,57 €	24,60 €
-	HSB5-55/B	M5	55	10	8	20	-	-	-	27,24 €
HSE5-60/B	HSB5-60/B	M5	60	10	8	20	-	✓	19,77 €	29,83 €
HSE5-70/B	HSB5-70/B	M5	70	10	8	20	✓	-	21,64 €	35,12 €
HSE6-10/B	-	M6	10	10	10	20	✓	-	15,77 €	-
HSE6-12/B	-	M6	12	12	10	20	✓	-	16,11 €	-
HSE6-15/B	-	M6	15	15	10	20	✓	-	16,96 €	-
HSE6-18/B	-	M6	18	18	10	20	✓	-	17,92 €	-
HSE6-20/B	-	M6	20	20	10	20	✓	-	18,62 €	-
HSE6-25/B	-	M6	25	25	10	20	✓	-	20,32 €	-
HSE6-30/B	-	M6	30	13	10	20	✓	-	21,16 €	-
HSE6-35/B	-	M6	35	13	10	20	✓	-	22,06 €	-
HSE6-40/B	-	M6	40	13	10	20	✓	-	22,91 €	-
HSE6-45/B	-	M6	45	13	10	20	✓	-	23,89 €	-
HSE6-50/B	-	M6	50	13	10	20	✓	-	24,94 €	-
HSE6-55/B	-	M6	55	13	10	20	✓	-	25,93 €	-
HSE6-60/B	-	M6	60	13	10	20	✓	-	27,48 €	-
HSE6-70/B	-	M6	70	13	10	20	-	-	29,65 €	-
HSE6-80/B	-	M6	80	13	10	20	✓	-	30,77 €	-

* Depending on availability - Dimensions in mm

Our other products

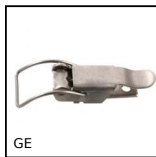


Toggle latches,
Standard



Actuator guide kit,
Coupling for threaded
cylinder end



Parallel axis helical
gear, Machined plastic
(delrin)

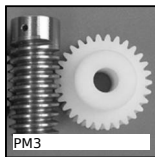

Worm and wheel set,
Machined plastic
(delrin)



Closed linear
precision bearing,
Economy range



 
Worm and wheel set,
Non hardened steel



T type tooth bar
stock, T10



Shaft for worm and
wheel reducer CHMR
and CHM, CHMR and
CHM gearbox...



Steel spur gear, Steel
20NCD2



Miniature friction
hinge, Friction



Adjustable foot for
aluminium profile,



Diabolo shaped elasto
mount, Steel

Complementary products



Hexagonal spacer,
Brass



Hexagonal spacer,
Steel