


# Hexagonal spacer

Ste Bra Stock

HSE  
HSB

Steel or Brass

- Female/female pillar
- Material: Zn3-5BL steel zinc-plated by electrolysis or brass
- Sold by the packet

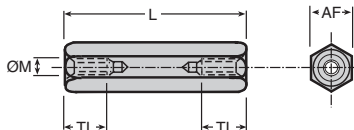

## DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix -20%	-30%	On request	

Part number	Thread	Qty. per packet	Stock*		Price per packet					
			Steel	Brass	Steel	Brass				
-	HSB2-5/B	M2	5	5	4	20	-	✓	-	3,64 €
-	HSB2-8/B	M2	8	8	4	20	-	✓	-	3,86 €
-	HSB2-10/B	M2	10	10	4	20	-	✓	-	4,09 €
-	HSB2-12/B	M2	12	12	4	20	-	✓	-	4,41 €
-	HSB2-15/B	M2	15	15	4	20	-	✓	-	5,78 €
-	HSB2-20/B	M2	20	20	4	20	-	✓	-	6,91 €
-	HSB2-25/B	M2	25	8	4	20	-	✓	-	10,40 €
-	HSB2-35/B	M2	35	8	4	20	-	✓	-	13,99 €
-	HSB2-40/B	M2	40	8	4	20	-	✓	-	17,35 €
HSE2.5-5/B	HSB2.5-5/B	M2,5	5	5	5	20	✓	✓	5,97 €	3,41 €
-	HSB2.5-8/B	M2,5	8	8	5	20	-	✓	-	3,74 €
HSE2.5-10/B	HSB2.5-10/B	M2,5	10	10	5	20	✓	✓	6,91 €	4,67 €
-	HSB2.5-12/B	M2,5	12	12	5	20	-	✓	-	4,31 €
HSE2.5-15/B	-	M2,5	15	15	5	20	-	-	8,46 €	-
HSE2.5-20/B	HSB2.5-20/B	M2,5	20	20	5	20	-	-	10,46 €	6,84 €
HSE2.5-30/B	HSB2.5-30/B	M2,5	30	10	5	20	-	-	9,95 €	9,09 €
-	HSB3-5/B	M3	5	5	5	20	-	✓	-	3,20 €
HSE3-8/B	HSB3-8/B	M3	8	8	5	20	✓	✓	4,82 €	3,51 €
HSE3-10/B	HSB3-10/B	M3	10	10	5	20	✓	✓	4,38 €	3,74 €
HSE3-12/B	HSB3-12/B	M3	12	12	5	20	✓	✓	4,61 €	4,09 €
HSE3-15/B	HSB3-15/B	M3	15	15	5	20	✓	✓	5,78 €	4,41 €
HSE3-18/B	HSB3-18/B	M3	18	18	5	20	✓	-	6,37 €	4,98 €
HSE3-20/B	HSB3-20/B	M3	20	20	5	20	✓	✓	5,98 €	5,50 €
HSE3-25/B	HSB3-25/B	M3	25	10	5	20	✓	✓	5,91 €	6,33 €
HSE3-30/B	HSB3-30/B	M3	30	10	5	20	✓	-	7,07 €	7,23 €
HSE3-35/B	HSB3-35/B	M3	35	10	5	20	✓	✓	7,43 €	8,48 €
HSE3-40/B	HSB3-40/B	M3	40	10	5	20	✓	✓	6,66 €	10,49 €
HSE3-45/B	HSB3-45/B	M3	45	10	5	20	-	-	8,07 €	13,51 €
HSE3-50/B	HSB3-50/B	M3	50	10	5	20	-	-	13,04 €	12,87 €
HSE3-55/B	-	M3	55	10	5	20	-	-	13,61 €	-
HSE3-60/B	HSB3-60/B	M3	60	10	5	20	-	-	12,09 €	14,89 €
HSE3-70/B	-	M3	70	10	5	20	-	-	15,40 €	-

\*Depending on availability - Dimensions in mm

## DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number		Thread ØM	L	TL	AF	Qty. per packet	Stock*		Price per packet	
Steel	Brass						Steel	Brass	Steel	Brass
HSE4-8/B	HSB4-8/B	M4	8	8	7	20	✓	✓	5,71 €	5,12 €
HSE4-10/B	HSB4-10/B	M4	10	10	7	20	✓	-	5,87 €	5,43 €
HSE4-12/B	-	M4	12	12	7	20	✓	-	6,24 €	-
HSE4-15/B	HSB4-15/B	M4	15	15	7	20	✓	✓	6,81 €	6,98 €
HSE4-20/B	HSB4-20/B	M4	20	20	7	20	✓	✓	8,31 €	8,82 €
HSE4-25/B	HSB4-25/B	M4	25	10	7	20	✓	-	8,50 €	10,13 €
HSE4-30/B	HSB4-30/B	M4	30	10	7	20	✓	✓	9,19 €	11,85 €
HSE4-35/B	HSB4-35/B	M4	35	10	7	20	✓	-	9,79 €	14,09 €
HSE4-40/B	HSB4-40/B	M4	40	10	7	20	✓	✓	10,28 €	17,35 €
HSE4-45/B	HSB4-45/B	M4	45	10	7	20	✓	✓	10,57 €	19,32 €
HSE4-50/B	-	M4	50	10	7	20	✓	-	15,74 €	-
HSE4-55/B	-	M4	55	10	7	20	✓	-	16,48 €	-
HSE4-60/B	-	M4	60	10	7	20	✓	-	17,23 €	-
HSE4-70/B	-	M4	70	10	7	20	✓	-	18,79 €	-
HSE4-80/B	-	M4	80	10	7	20	✓	-	20,45 €	-
HSE5-10/B	HSB5-10/B	M5	10	10	8	20	-	-	6,61 €	6,45 €
HSE5-12/B	-	M5	12	12	8	20	✓	-	7,92 €	-
HSE5-15/B	HSB5-15/B	M5	15	15	8	20	✓	-	8,62 €	8,40 €
HSE5-20/B	HSB5-20/B	M5	20	20	8	20	✓	-	11,96 €	10,39 €
HSE5-25/B	HSB5-25/B	M5	25	10	8	20	✓	-	12,86 €	12,11 €
HSE5-30/B	HSB5-30/B	M5	30	10	8	20	✓	✓	13,89 €	14,09 €
HSE5-35/B	HSB5-35/B	M5	35	10	8	20	-	-	14,50 €	18,02 €
HSE5-40/B	-	M5	40	10	8	20	✓	-	15,28 €	-
HSE5-45/B	-	M5	45	10	8	20	-	-	16,27 €	-
HSE5-50/B	HSB5-50/B	M5	50	10	8	20	✓	-	17,57 €	24,60 €
-	HSB5-55/B	M5	55	10	8	20	-	-	-	27,24 €
HSE5-60/B	HSB5-60/B	M5	60	10	8	20	-	✓	19,77 €	29,83 €
HSE5-70/B	HSB5-70/B	M5	70	10	8	20	✓	-	21,64 €	35,12 €
HSE6-10/B	-	M6	10	10	10	20	✓	-	15,77 €	-
HSE6-12/B	-	M6	12	12	10	20	✓	-	16,11 €	-
HSE6-15/B	-	M6	15	15	10	20	✓	-	16,96 €	-
HSE6-18/B	-	M6	18	18	10	20	✓	-	17,92 €	-
HSE6-20/B	-	M6	20	20	10	20	✓	-	18,62 €	-
HSE6-25/B	-	M6	25	25	10	20	✓	-	20,32 €	-
HSE6-30/B	-	M6	30	13	10	20	✓	-	21,16 €	-
HSE6-35/B	-	M6	35	13	10	20	✓	-	22,06 €	-
HSE6-40/B	-	M6	40	13	10	20	✓	-	22,91 €	-
HSE6-45/B	-	M6	45	13	10	20	✓	-	23,89 €	-
HSE6-50/B	-	M6	50	13	10	20	✓	-	24,94 €	-
HSE6-55/B	-	M6	55	13	10	20	✓	-	25,93 €	-
HSE6-60/B	-	M6	60	13	10	20	✓	-	27,48 €	-
HSE6-70/B	-	M6	70	13	10	20	-	-	29,65 €	-
HSE6-80/B	-	M6	80	13	10	20	✓	-	30,77 €	-

\* Depending on availability - Dimensions in mm

## Our other products



 
FGWA

End support, With base



ACAss

Stainless steel splined shaft, Stainless steel



BMF

Knurled knob - female, Knurled - through threaded



PW\_PWG15

Worm - precision range, Stainless steel



GLT3E-58

Telescopic drawer,



IN1

Internal gear, Steel 20NCD2



DER90

Stainless steel AC asynchronous motor 1.1 - 1.5kW, 1.1 to 1.5kW



SLS

Bearing block for leadscrew, Floating Drylin® bearing block



EHD08-9

Internal epicyclic servo reducers, from 35 to 50 Nm



PFL

P-FLEX Coupling, Set screw



T5-BAR

T type tooth bar stock, T5



MBF

Threaded blocking clamp, Threaded locking clamp

## Complementary products



HSE-HSB

Hexagonal spacer, Steel



MPB

Hexagonal spacer, Brass