
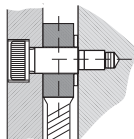
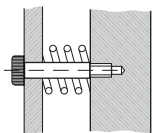
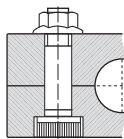


HSSs

A2 stainless steel

- **Centering and clamping function**
- Ground shoulder, tolerance f_9
- Material:
stainless steel A2

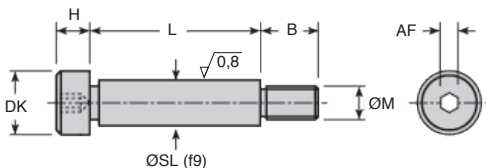

| Part number | Thread | | ØSL | | | Qty | | | Price each | |
|--------------|--------|------|-----|------|------|-------|-----|----|------------|---------|
| | ØM | Pas | L | (f9) | B | DK | H | AF | | per box |
| HSS5-10/SS/B | M5 | 0,80 | 10 | 6 | 9,50 | 10,22 | 4,5 | 3 | 10 | 45,85 € |
| HSS5-12/SS/B | M5 | 0,80 | 12 | 6 | 9,50 | 10,22 | 4,5 | 3 | 10 | 45,96 € |
| HSS5-16/SS/B | M5 | 0,80 | 16 | 6 | 9,50 | 10,22 | 4,5 | 3 | 10 | 47,66 € |
| HSS5-20/SS/B | M5 | 0,80 | 20 | 6 | 9,50 | 10,22 | 4,5 | 3 | 10 | 53,64 € |
| HSS5-25/SS/B | M5 | 0,80 | 25 | 6 | 9,50 | 10,22 | 4,5 | 3 | 10 | 62,09 € |
| HSS5-30/SS/B | M5 | 0,80 | 30 | 6 | 9,50 | 10,22 | 4,5 | 3 | 10 | 64,44 € |
| HSS5-40/SS/B | M5 | 0,80 | 40 | 6 | 9,50 | 10,22 | 4,5 | 3 | 10 | 70,65 € |

Dimensions in mm

| Part number | Thread | | ØSL | | | | | | Qty per box | Price each 1 to 5 |
|----------------|--------|------|-----|------|-------|-------|-----|----|-------------|-------------------|
| | ØM | Pas | L | (f9) | B | DK | H | AF | | |
| HSS6-12/SS/B | M6 | 1,00 | 12 | 8 | 11,00 | 13,27 | 5,5 | 4 | 10 | 55,09 € |
| HSS6-16/SS/B | M6 | 1,00 | 16 | 8 | 11,00 | 13,27 | 5,5 | 4 | 10 | 54,07 € |
| HSS6-20/SS/B | M6 | 1,00 | 20 | 8 | 11,00 | 13,27 | 5,5 | 4 | 10 | 62,47 € |
| HSS6-25/SS/B | M6 | 1,00 | 25 | 8 | 11,00 | 13,27 | 5,5 | 4 | 10 | 68,48 € |
| HSS6-30/SS/B | M6 | 1,00 | 30 | 8 | 11,00 | 13,27 | 5,5 | 4 | 10 | 69,31 € |
| HSS6-40/SS/B | M6 | 1,00 | 40 | 8 | 11,00 | 13,27 | 5,5 | 4 | 10 | 73,66 € |
| HSS6-50/SS/B | M6 | 1,00 | 50 | 8 | 11,00 | 13,27 | 5,5 | 4 | 10 | 83,27 € |
| HSS8-16/SS/B | M8 | 1,25 | 16 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 58,00 € |
| HSS8-20/SS/B | M8 | 1,25 | 20 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 61,12 € |
| HSS8-25/SS/B | M8 | 1,25 | 25 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 67,07 € |
| HSS8-30/SS/B | M8 | 1,25 | 30 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 83,22 € |
| HSS8-40/SS/B | M8 | 1,25 | 40 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 76,92 € |
| HSS8-50/SS/B | M8 | 1,25 | 50 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 86,15 € |
| HSS8-60/SS/B | M8 | 1,25 | 60 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 94,95 € |
| HSS8-70/SS/B | M8 | 1,25 | 70 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 115,64 € |
| HSS8-80/SS/B | M8 | 1,25 | 80 | 10 | 13,00 | 16,27 | 7 | 5 | 10 | 109,79 € |
| HSS10-16/SS/B | M10 | 1,50 | 16 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 45,46 € |
| HSS10-20/SS/B | M10 | 1,50 | 20 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 50,67 € |
| HSS10-25/SS/B | M10 | 1,50 | 25 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 48,66 € |
| HSS10-30/SS/B | M10 | 1,50 | 30 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 53,62 € |
| HSS10-40/SS/B | M10 | 1,50 | 40 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 55,83 € |
| HSS10-50/SS/B | M10 | 1,50 | 50 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 58,49 € |
| HSS10-60/SS/B | M10 | 1,50 | 60 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 61,40 € |
| HSS10-70/SS/B | M10 | 1,50 | 70 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 72,66 € |
| HSS10-80/SS/B | M10 | 1,50 | 80 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 68,81 € |
| HSS10-100/SS/B | M10 | 1,50 | 100 | 12 | 16,00 | 18,27 | 9 | 6 | 5 | 136,06 € |
| HSS12-30/SS/B | M12 | 1,75 | 30 | 16 | 18,00 | 24,33 | 11 | 8 | 5 | 89,48 € |
| HSS12-40/SS/B | M12 | 1,75 | 40 | 16 | 18,00 | 24,33 | 11 | 8 | 5 | 89,39 € |
| HSS12-50/SS/B | M12 | 1,75 | 50 | 16 | 18,00 | 24,33 | 11 | 8 | 5 | 124,13 € |
| HSS12-60/SS/B | M12 | 1,75 | 60 | 16 | 18,00 | 24,33 | 11 | 8 | 5 | 151,32 € |
| HSS12-70/SS/B | M12 | 1,75 | 70 | 16 | 18,00 | 24,33 | 11 | 8 | 5 | 121,47 € |
| HSS12-80/SS/B | M12 | 1,75 | 80 | 16 | 18,00 | 24,33 | 11 | 8 | 5 | 277,97 € |
| HSS12-100/SS/B | M12 | 1,75 | 100 | 16 | 18,00 | 24,33 | 11 | 8 | 5 | 179,57 € |
| HSS16-40/SS/B | M16 | 2,00 | 40 | 20 | 22,00 | 30,33 | 14 | 10 | 3 | 123,79 € |
| HSS16-50/SS/B | M16 | 2,00 | 50 | 20 | 22,00 | 30,33 | 14 | 10 | 3 | 182,37 € |
| HSS16-60/SS/B | M16 | 2,00 | 60 | 20 | 22,00 | 30,33 | 14 | 10 | 3 | 148,46 € |
| HSS16-70/SS/B | M16 | 2,00 | 70 | 20 | 22,00 | 30,33 | 14 | 10 | 3 | 166,80 € |
| HSS16-80/SS/B | M16 | 2,00 | 80 | 20 | 22,00 | 30,33 | 14 | 10 | 3 | 211,26 € |

Dimensions in mm

Our other products



Horizontal hook toggle clamp, Horizontal Hook clamp - stainless steel



Modular cylindrical brush, PBT polyester bristles



Universal fastener for aluminium profile, Universal



Flanged bronze nut, Bronze - 1 thread



Rigging screw (hook/eye), Steel



Mushroom headed button Hygienic Usit®, With male thread and high head



Flanged polymer nut, Polymer (Iglidur®) - 1 thread



Articulated foot with sheet metal base Ø100, Articulated foot



Spring loaded toggle latch, Standard



Stainless steel bevel gear, 2:1



Accessories, Fixing kit



Roll of hinge without pin, Plastic hinge

Complementary products



Shoulder screw stainless steel 416, Pre-treated 416 stainless steel



Shoulder screw stainless steel 303, Stainless steel 303



Shoulder screw ISO7379, Hardened Steel class 12.9



Hexagonal nut DIN934, A2 Stainless steel