

Steel or cast iron

Pitch
14mm

Belt width 55mm

- For use with RPP14 belt
- Pitch: 14mm
- Material:
Cast iron or phosphated steel
depending on size

Supplied with
pilot bore






Accessories

- Belts RPP14
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- We are unable to modify these parts.

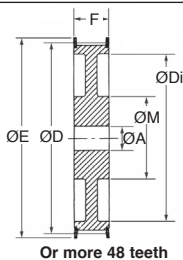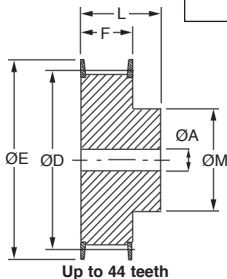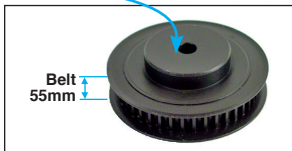

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Material	No. of teeth	PCD Ø external	flange			F	L	Pilot bore		Price each 1 to 5
				OE	OM	ODi			**OA	ØA	
28HTD14M-55F	Steel	28	124,78	122,12	128	100	-	70	85	24	89,58 €
29HTD14M-55F		29	129,23	126,57	138	100	-	70	85	24	119,44 €
30HTD14M-55F		30	133,69	130,99	138	100	-	70	85	24	111,16 €
32HTD14M-55F		32	142,60	139,88	154	100	-	70	85	24	125,82 €
34HTD14M-55F		34	151,52	148,79	160	100	-	70	85	24	142,46 €
36HTD14M-55F		36	160,43	157,68	168	100	-	70	85	24	159,29 €
38HTD14M-55F		38	169,34	166,60	183	120	-	70	85	24	167,41 €
40HTD14M-55F		40	178,25	175,49	188	120	-	70	85	24	187,60 €
44HTD14M-55F	Cast	44	196,08	193,28	211	120	-	70	85	24	228,27 €
48HTD14M-55F		48	213,90	211,11	226	135	170	70	70	24	212,51 €
56HTD14M-55F		56	249,55	246,76	256	135	207	70	70	28	265,15 €
64HTD14M-55F		64	285,21	282,41	296	135	240	70	70	28	270,36 €

Dimensions in mm

Our other products



BLM
Spring loaded plunger with ball tip, Stainless steel body



PML
Solid foot mount for heavy loads, Ø 100, 120 or 150




PF40
Worm and wheel gear reducer, up to 18 Nm



DER80
Stainless steel AC asynchronous motor 0.55 - 0.75kW, 0.55 to 0.75kW



 PSG125
Spur gear - precision range, Pre-hardened Steel 35NCD6



RPPM
RPP type belt per metre, RPP5 Steel cored polyurethane



SCR
Suction cup threaded insert, Insert for suction cup - Socket screw



PRF_ROUL_F_
Castor for aluminium profile, With brake



DOMI120
Accessories, Clamping lever



PRF_FIX_STD
Fastener for aluminium profile, Standard fastener




CHNrb
Warning chain with red and white links, Steel



PRS100
Stainless steel articulated foot Ø100, Ø 100

 Complementary products



RPP14
RPP heavy duty timing belt, RPP14



GTC
Belt tensioner, For standard applications