

Steel or cast iron

Pitch
14mm

Belt width 55mm

- For use with RPP14 belt
- Pitch: 14mm
- Material:
Cast iron or phosphated steel
depending on size

Supplied with
pilot bore





Accessories


- Belts RPP14
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- We are unable to modify these parts.

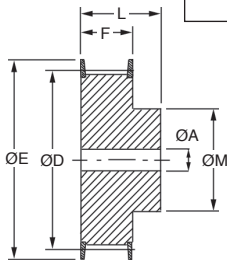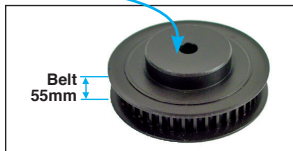

Up to 44 teeth

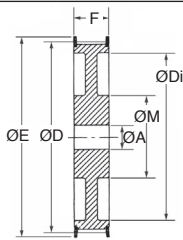

Or more 48 teeth

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -12%	On request	

Part number	Material	No. of teeth	PCD Ø external	flange			ØDi	F	L	Pilot bore		Price each 1 to 5
				OE	OM	ØDi				**ØA	ØA	
28HTD14M-55F	Steel	28	124,78	122,12	128	100	-	70	85	24	89,58 €	
29HTD14M-55F		29	129,23	126,57	138	100	-	70	85	24	119,44 €	
30HTD14M-55F		30	133,69	130,99	138	100	-	70	85	24	111,16 €	
32HTD14M-55F		32	142,60	139,88	154	100	-	70	85	24	125,82 €	
34HTD14M-55F		34	151,52	148,79	160	100	-	70	85	24	142,46 €	
36HTD14M-55F		36	160,43	157,68	168	100	-	70	85	24	159,29 €	
38HTD14M-55F		38	169,34	166,60	183	120	-	70	85	24	167,41 €	
40HTD14M-55F		40	178,25	175,49	188	120	-	70	85	24	187,60 €	
44HTD14M-55F	Cast	44	196,08	193,28	211	120	-	70	85	24	228,27 €	
48HTD14M-55F		48	213,90	211,11	226	135	170	70	70	28	212,51 €	
56HTD14M-55F		56	249,55	246,76	256	135	207	70	70	28	265,15 €	
64HTD14M-55F		64	285,21	282,41	296	135	240	70	70	28	270,36 €	

Dimensions in mm

Our other products



PITA

Locking bolt, with T handle



PGNT

Thermoplastic T handle, With threaded spindle



MCLred

Reducing sleeve female/female, Cylindrical - steel



UGH20

H Type Guide units, For $\varnothing 20$ actuators



BSB

Ballscrew bearing unit, Support



BAN

Angular clamp, Adjustable




PAT123

Pressed stainless steel articulating foot $\varnothing 123$, $\varnothing 123$



AWMP

 Aluminium shaft for linear guide, Aluminium



VP

Small 6 lobe threaded handle - male, Duroplast - Steel



EHD12

Internal epicyclic servo reducers, from 60 to 140 Nm



PTA80ssEB


Articulated foot with sheet metal base $\varnothing 80$, Articulated foot



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW

Complementary products

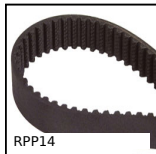

RPP14

RPP heavy duty timing belt, RPP14



GTC

Belt tensioner, For standard applications