

HTD type timing pulley



Pitch 3mm

Aluminium

Belt width 9mm





- For use with RPP3 belt
- Pitch: 3mm
- Material: aluminium

Accessories

- Belts RPP3
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size customer
- We are unable to modify these parts.

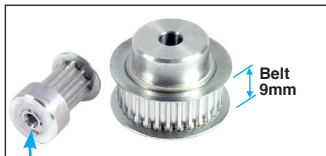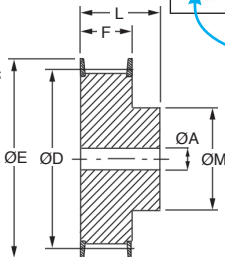

Supplied with pilot bore

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No. of teeth	PCD Ø	External Flange			F	L	Pilot bore ** ØA	Price each 1 to 5
			ØD	ØE	ØM				
10HTD3M-09F	10	9,55	8,79	13,0	13,0	10,2	17,5	Solid	6,33 €
12HTD3M-09F	12	11,46	10,70	15,0	15,0	10,2	17,5	Solid	6,33 €
14HTD3M-09F	14	13,37	12,61	16,0	16,0	10,2	17,5	Solid	6,45 €
15HTD3M-09F	15	14,32	13,56	17,5	17,5	10,2	17,5	Solid	6,45 €
16HTD3M-09F	16	15,28	14,52	17,5	10,0	12,8	20,6	4	6,91 €
18HTD3M-09F	18	17,19	16,43	20,0	11,0	12,8	20,6	6	7,02 €
20HTD3M-09F	20	19,10	18,34	23,0	13,0	12,8	20,6	6	7,07 €
21HTD3M-09F	21	20,05	19,29	25,0	14,0	12,8	20,6	6	7,29 €
22HTD3M-09F	22	21,01	20,25	25,0	14,0	12,8	20,6	6	7,54 €
24HTD3M-09F	24	22,92	22,16	25,0	14,0	12,8	20,6	6	8,01 €
26HTD3M-09F	26	24,83	24,07	28,0	16,0	12,8	20,6	6	8,18 €
28HTD3M-09F	28	26,74	25,98	32,0	18,0	12,8	20,6	6	8,31 €
30HTD3M-09F	30	28,65	27,89	32,0	20,0	12,8	20,6	6	8,47 €
32HTD3M-09F	32	30,56	29,80	36,0	22,0	12,8	20,6	6	9,03 €
36HTD3M-09F	36	34,38	33,62	39,0	26,0	13,4	22,2	6	9,59 €
40HTD3M-09F	40	38,20	37,44	42,0	28,0	13,4	22,2	6	10,57 €
44HTD3M-09F	44	42,02	41,26	48,0	33,0	13,4	22,2	6	12,19 €
48HTD3M-09	48	45,84	45,08	-	33,0	13,4	22,2	8	13,21 €
60HTD3M-09	60	57,30	56,54	-	33,0	13,4	22,2	8	14,81 €
72HTD3M-09	72	68,75	67,99	-	33,0	13,4	22,2	8	16,98 €

*Depending on availability - Dimensions in mm

Our other products



PR85

Articulated foot Ø83,
Ø 83



PRF_CLIP_22

Cable clip for
aluminium profile, For
electric and
pneumatic cables



DB

Steel bevel gear, 2:1



PR40

Articulated foot Ø40,
Ø 40



DOMI50

Connecting kits, ZX
linking kit



PARF110

Pressed steel base
rigid foot, Swivelling
Ø110



BOXKU

Boxed set of half
round (Woodruff) keys
NFE22179, Boxed set
of half ...



Q6

Deep groove ball
bearing, Steel



PR40

Articulated foot Ø50,
Ø 50



EHD08-3

Internal epicyclic
servo reducers, from



PRF4590

 
Standard aluminium
profile, 45 x 90 mm



F7-SN

Multifunction display,
Articulated support

Complementary products



RPP3

RPP heavy duty
timing belt, RPP3



GTC

Belt tensioner, For
standard applications