

HTD type timing pulley



Pitch 3mm

Aluminium

Belt width 9mm





- For use with RPP3 belt
- Pitch: 3mm
- Material: aluminium

Accessories

- Belts RPP3
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size customer
- We are unable to modify these parts.

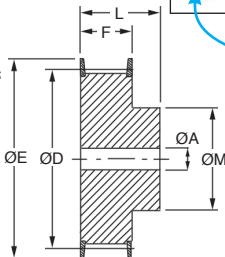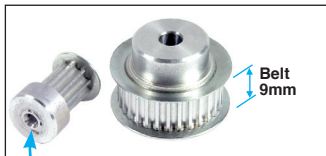

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	No. of teeth	PCD Ø	External Flange			F	L	Pilot bore ** ØA	Solid	Price each 1 to 5
			ØD	OE	ØM					
10HTD3M-09F	10	9,55	8,79	13,0	13,0	10,2	17,5	Solid	✓	6,33 €
12HTD3M-09F	12	11,46	10,70	15,0	15,0	10,2	17,5	Solid	✓	6,33 €
14HTD3M-09F	14	13,37	12,61	16,0	16,0	10,2	17,5	Solid	✓	6,45 €
15HTD3M-09F	15	14,32	13,56	17,5	17,5	10,2	17,5	Solid	✓	6,45 €
16HTD3M-09F	16	15,28	14,52	17,5	10,0	12,8	20,6	4	✓	6,91 €
18HTD3M-09F	18	17,19	16,43	20,0	11,0	12,8	20,6	6	✓	7,02 €
20HTD3M-09F	20	19,10	18,34	23,0	13,0	12,8	20,6	6	✓	7,07 €
21HTD3M-09F	21	20,05	19,29	25,0	14,0	12,8	20,6	6	✓	7,29 €
22HTD3M-09F	22	21,01	20,25	25,0	14,0	12,8	20,6	6	✓	7,54 €
24HTD3M-09F	24	22,92	22,16	25,0	14,0	12,8	20,6	6	✓	8,01 €
26HTD3M-09F	26	24,83	24,07	28,0	16,0	12,8	20,6	6	✓	8,18 €
28HTD3M-09F	28	26,74	25,98	32,0	18,0	12,8	20,6	6	✓	8,31 €
30HTD3M-09F	30	28,65	27,89	32,0	20,0	12,8	20,6	6	✓	8,47 €
32HTD3M-09F	32	30,56	29,80	36,0	22,0	12,8	20,6	6	✓	9,03 €
36HTD3M-09F	36	34,38	33,62	39,0	26,0	13,4	22,2	6	✓	9,59 €
40HTD3M-09F	40	38,20	37,44	42,0	28,0	13,4	22,2	6	✓	10,57 €
44HTD3M-09F	44	42,02	41,26	48,0	33,0	13,4	22,2	6	✓	12,19 €
48HTD3M-09	48	45,84	45,08	-	33,0	13,4	22,2	8	✓	13,21 €
60HTD3M-09	60	57,30	56,54	-	33,0	13,4	22,2	8	✓	14,81 €
72HTD3M-09	72	68,75	67,99	-	33,0	13,4	22,2	8	✓	16,98 €

*Depending on availability - Dimensions in mm

Our other products



NKX

Combined bearing without inner ring, Needle and ball bearings



VTLF

3 lobed handle, Polyamide - Brass



P70

Worm and wheel gear reducer, up to 164 Nm



CHAFR-MINI

Miniature friction hinge, Friction



TPEF

Castor for aluminium profile, Fixed



BAN

Angular clamp, Standard



DILC

Indexing plunger with cam, with cam




AT5-16ECO

AT type timing pulley, Economy range - AT5 aluminium



AC

 Strike for toggle latch, 15mm



CFC

Spring loaded position switch, Electric



RHTtcss

 
High Temperature Castor, up to 200kg



MEB

Moulded plastic bevel gear (nylon), 1:1

Complementary products



RPP3

RPP heavy duty timing belt, RPP3



GTC

Belt tensioner, For standard applications