

HTD type toothed bar stock



HTD5M-BAR

Aluminium




- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodising
- Finish : Supplied non-anodised

Info.

- We are unable to modify this product

Accessories

- RPP5 belt (tome 4 p.28)

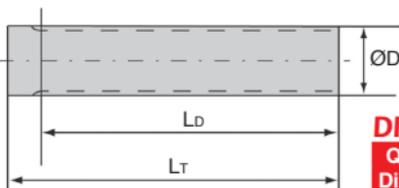

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	Z Teeth	ØD External	Length of teeth L _d	Total length L _T	Price each
12HTD5M-BAR	12	17,96	150	160	10,88 €
13HTD5M-BAR	13	19,55	150	160	11,94 €
14HTD5M-BAR	14	21,14	175	200	15,12 €
15HTD5M-BAR	15	22,73	175	200	16,58 €
16HTD5M-BAR	16	24,33	175	200	18,04 €
17HTD5M-BAR	17	25,92	175	200	18,22 €
18HTD5M-BAR	18	27,51	200	200	21,53 €
19HTD5M-BAR	19	29,10	200	200	23,50 €
20HTD5M-BAR	20	30,69	200	200	25,22 €
21HTD5M-BAR	21	32,28	200	200	26,30 €
22HTD5M-BAR	22	33,88	200	200	27,33 €
23HTD5M-BAR	23	35,47	200	200	29,42 €
24HTD5M-BAR	24	37,06	200	200	31,72 €
25HTD5M-BAR	25	38,65	200	200	33,91 €
26HTD5M-BAR	26	40,24	200	200	37,34 €
27HTD5M-BAR	27	41,83	200	200	37,48 €
28HTD5M-BAR	28	43,42	200	200	41,17 €
30HTD5M-BAR	30	46,61	200	200	44,02 €
32HTD5M-BAR	32	49,79	200	200	47,01 €
34HTD5M-BAR	34	52,97	200	200	51,59 €
36HTD5M-BAR	36	56,16	200	200	59,29 €
38HTD5M-BAR	38	59,34	200	200	63,07 €
40HTD5M-BAR	40	62,52	200	200	68,49 €
42HTD5M-BAR	42	65,71	200	200	74,05 €
44HTD5M-BAR	44	68,89	200	200	87,49 €
45HTD5M-BAR	45	70,48	200	200	89,15 €
48HTD5M-BAR	48	75,26	200	200	97,96 €
50HTD5M-BAR	50	78,44	200	200	109,18 €
60HTD5M-BAR	60	94,36	200	200	147,89 €
72HTD5M-BAR	72	113,45	200	200	207,93 €

Dimensions in mm

- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Steel C40




Info.

- We are unable to modify this product

Accessories

- RPP8 belt (tome 4 p.28)

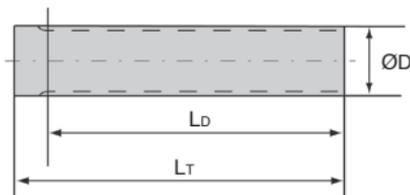

DISCOUNTS

Qty	1+	2+	4+
Disc.	List -20%	On request	

Part number	Z Teeth	ØD External	Length of teeth L _b	Total length L _T	Price each
18HTD8M-BAR	18	44,47	200	200	42,27 €
19HTD8M-BAR	19	47,01	200	200	45,05 €
20HTD8M-BAR	20	49,56	200	200	47,31 €
21HTD8M-BAR	21	52,11	200	200	49,25 €
22HTD8M-BAR	22	54,65	200	200	52,04 €
23HTD8M-BAR	23	57,20	200	200	53,96 €
24HTD8M-BAR	24	59,75	200	200	56,64 €
25HTD8M-BAR	25	62,29	200	200	58,38 €
26HTD8M-BAR	26	64,84	200	200	63,01 €
28HTD8M-BAR	28	69,93	200	200	69,04 €
30HTD8M-BAR	30	75,03	200	200	78,79 €
32HTD8M-BAR	32	80,12	200	200	91,48 €
34HTD8M-BAR	34	85,21	200	200	99,37 €
35HTD8M-BAR	35	87,76	200	200	109,91 €
36HTD8M-BAR	36	90,30	200	200	115,30 €
38HTD8M-BAR	38	95,40	200	200	128,78 €
40HTD8M-BAR	40	100,49	200	200	141,02 €
44HTD8M-BAR	44	110,67	200	200	166,90 €
48HTD8M-BAR	48	120,86	200	200	195,19 €

Dimensions in mm