 


# HTD type toothed bar stock



## HTD5M-BAR


Aluminium



- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodising
- Finish : Supplied non-anodised

### Info.

- We are unable to modify this product

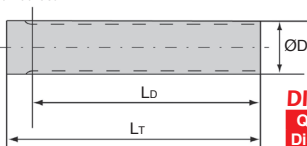

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request


Part number	Z Teeth	ØD External	Length of teeth L <sub>d</sub>	Total length L <sub>T</sub>	Price each
12HTD5M-BAR	12	17,96	150	160	9,91 €
13HTD5M-BAR	13	19,55	150	160	10,83 €
14HTD5M-BAR	14	21,14	175	200	13,80 €
15HTD5M-BAR	15	22,73	175	200	15,18 €
16HTD5M-BAR	16	24,33	175	200	16,50 €
17HTD5M-BAR	17	25,92	175	200	16,58 €
18HTD5M-BAR	18	27,51	200	200	19,72 €
19HTD5M-BAR	19	29,10	200	200	21,56 €
20HTD5M-BAR	20	30,69	200	200	23,26 €
21HTD5M-BAR	21	32,28	200	200	24,26 €
22HTD5M-BAR	22	33,88	200	200	25,25 €
23HTD5M-BAR	23	35,47	200	200	27,17 €
24HTD5M-BAR	24	37,06	200	200	29,18 €
25HTD5M-BAR	25	38,65	200	200	31,30 €
26HTD5M-BAR	26	40,24	200	200	34,55 €
27HTD5M-BAR	27	41,83	200	200	34,74 €
28HTD5M-BAR	28	43,42	200	200	38,32 €
30HTD5M-BAR	30	46,61	200	200	40,93 €
32HTD5M-BAR	32	49,79	200	200	43,69 €
34HTD5M-BAR	34	52,97	200	200	48,00 €
36HTD5M-BAR	36	56,16	200	200	55,27 €
38HTD5M-BAR	38	59,34	200	200	58,70 €
40HTD5M-BAR	40	62,52	200	200	63,77 €
42HTD5M-BAR	42	65,71	200	200	69,02 €
44HTD5M-BAR	44	68,89	200	200	81,76 €
45HTD5M-BAR	45	70,48	200	200	83,24 €
48HTD5M-BAR	48	75,26	200	200	91,58 €
50HTD5M-BAR	50	78,44	200	200	102,11 €
60HTD5M-BAR	60	94,36	200	200	138,47 €
72HTD5M-BAR	72	113,45	200	200	195,09 €

Dimensions in mm

## Our other products



 WS20  
Drylin® W rail, Rail



PRF JL6  
Lip seal for panel,  
Door seal - Ø 6mm



NTV91  
Spur gear coaxial  
gearbox, from 10 to  
35 Nm - In-line



HRV  
V-rail guidance  
Simple Select®  
system, Rail with  
carriage



RPP  
Connecting plate for  
RPP type timing belts,  
RPP14



BAP  
Plastic clamping  
collar, Ø10 - Ø20



RFVfp  
Stainless steel worm  
and wheel gearboxes,  
Mounting bracket



PTKFss  
Fixable foot for the  
food industry,  
Stainless steel - 3-A  
standard



HTD14M\_55  
HTD Heavy duty  
timing pulley, HTD14  
Steel



EHD06  
Internal epicyclic  
servo reducers, from  
8 to 19 Nm



CLSCLP  
Clevis components,  
short version, Steel -  
Short range



HK  
Manual locking clamp,  
Manual locking clamp  
LWL

## Complementary products



HTD8M-BAR  
HTD type tooth bar  
stock, HTD8